


E11106



Connecting cable with plug

ASTGH040MSS0010E04

Article no longer available - archive entry

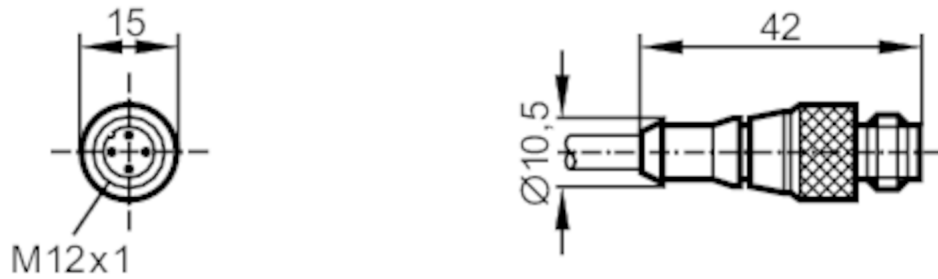

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...70

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 42

Materials TPU

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection

Cable: 10 m, PVC, orange, Ø 5 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated




E11106



Connecting cable with plug

ASTGH040MSS0010E04

Connection

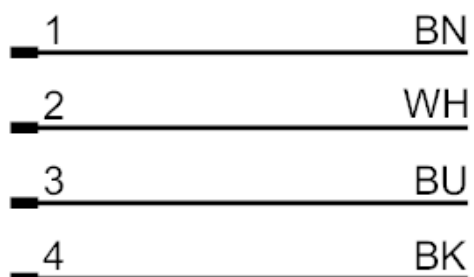

Core colours :

BK = black
BN = brown
BU = blue
WH = white

Article no longer available - archive entry