


E11218

Splitter box

ZD08F04HMSS0010H10



Article no longer available - archive entry

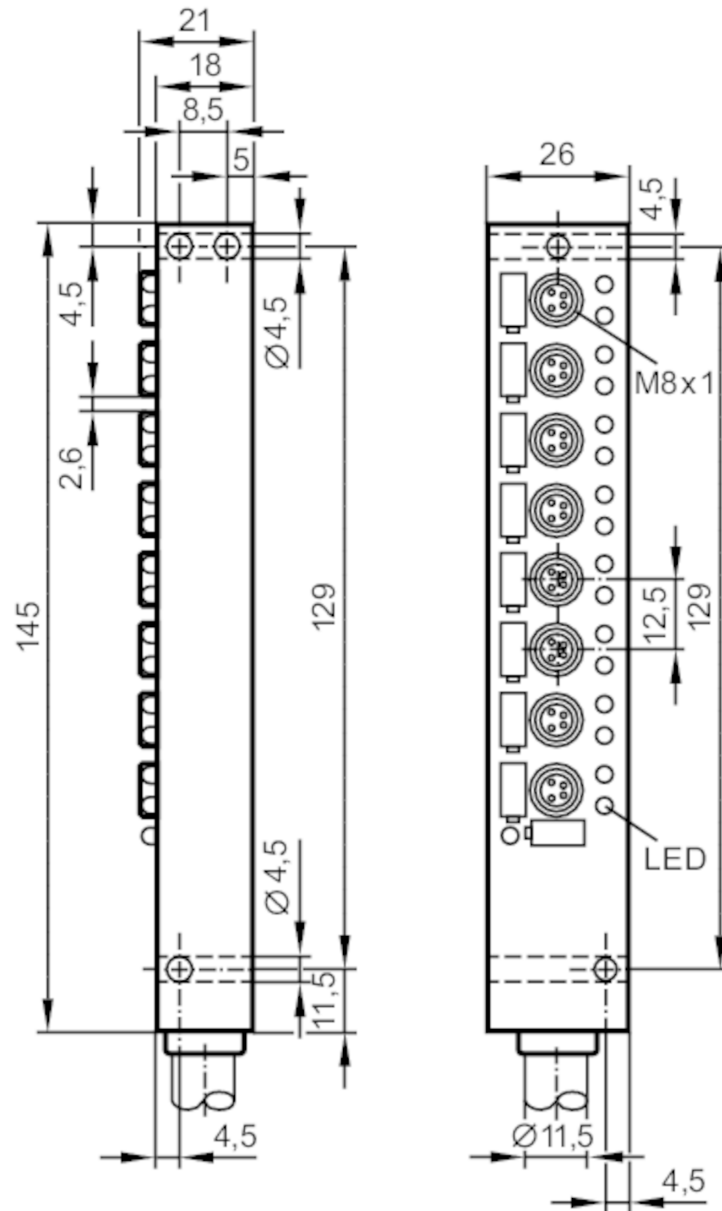

Application

Special feature Halogen-free; Gold-plated contacts; Drag chain suitability

Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III
Max. current load per module/slot	[A]	2
Max. current load total	[A]	6

Operating conditions


Ambient temperature	[°C]	-20...80
Protection		IP 67

E11218



Splitter box

 ZDO8F04HMSS0010H10

Mechanical data		
Weight	[g]	1443.2
Dimensions	[mm]	21 x 26 x 145
Materials		PBT-GF20; brass nickel-plated
Number of ports splitter box		8
Connector type		M8
Drag chain suitability		yes
Drag chain suitability	bending radius for flexible use	min. 10 x cable diameter
	travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s ²
	bending cycles	> 5 Mio.
	torsional strain	± 180 °/m
Displays / operating elements		
Display	switching status	16 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 10 m, PUR, Halogen-free, black, Ø 9.1 mm; 16 x 0.34 mm ² (42 x Ø 0.1 mm) + 2 x 0.75 mm ² (96 x Ø 0.1 mm)		
Electrical connection - slot		
Connector: 8 x M8; Moulded body: PBT-GF 20 / brass, nickel-plated; Contacts: gold-plated		
		


E11218



Splitter box

ZDO8F04HMSS0010H10

Connection

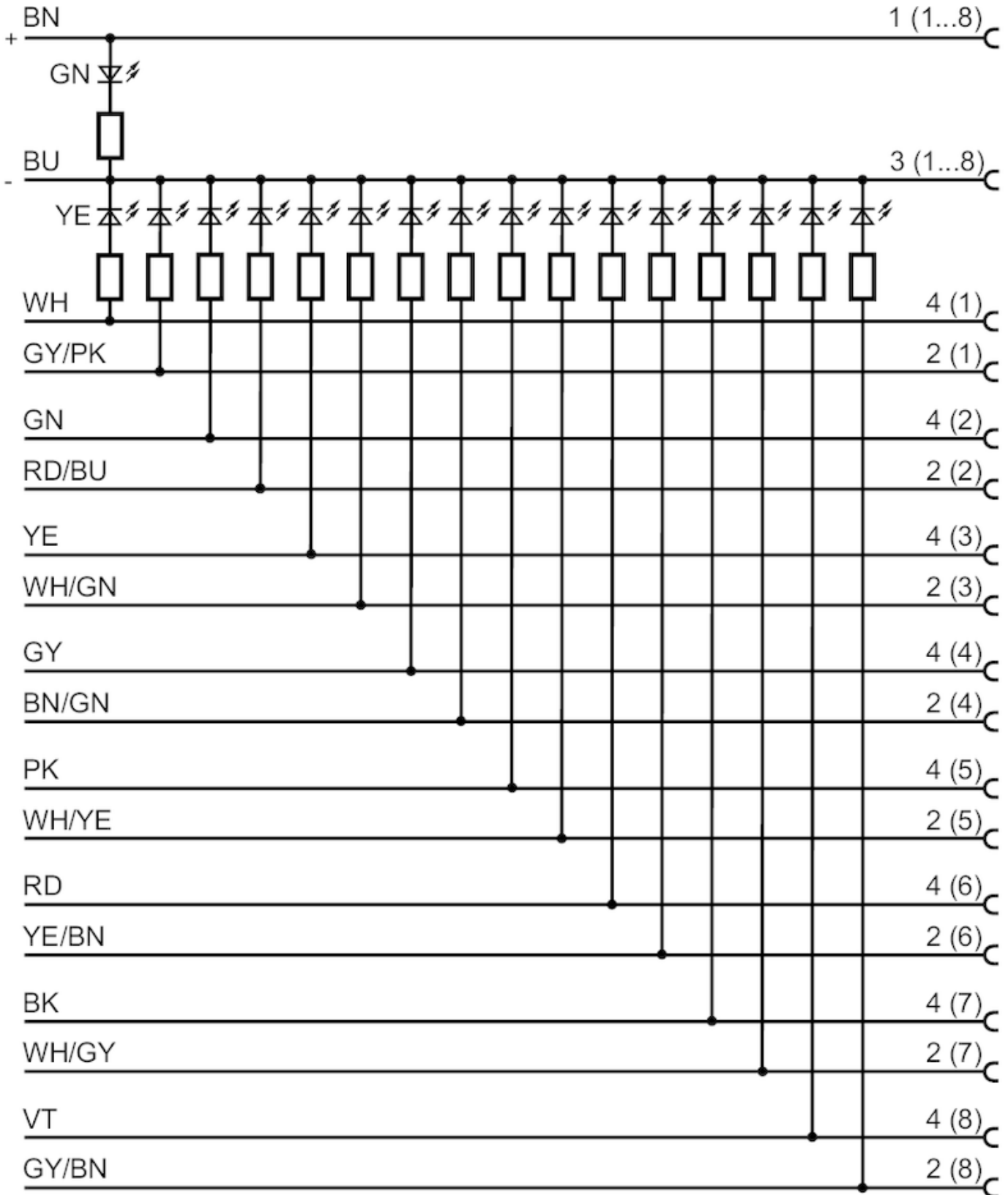

Core colours :

BK = black
 BN = brown

E11218

Splitter box

ZD08F04HMSS0010H10



Article no longer available - archive entry
