


# E12491



## Connection cable

VSTGN040ZDS0005L04STGP080--S

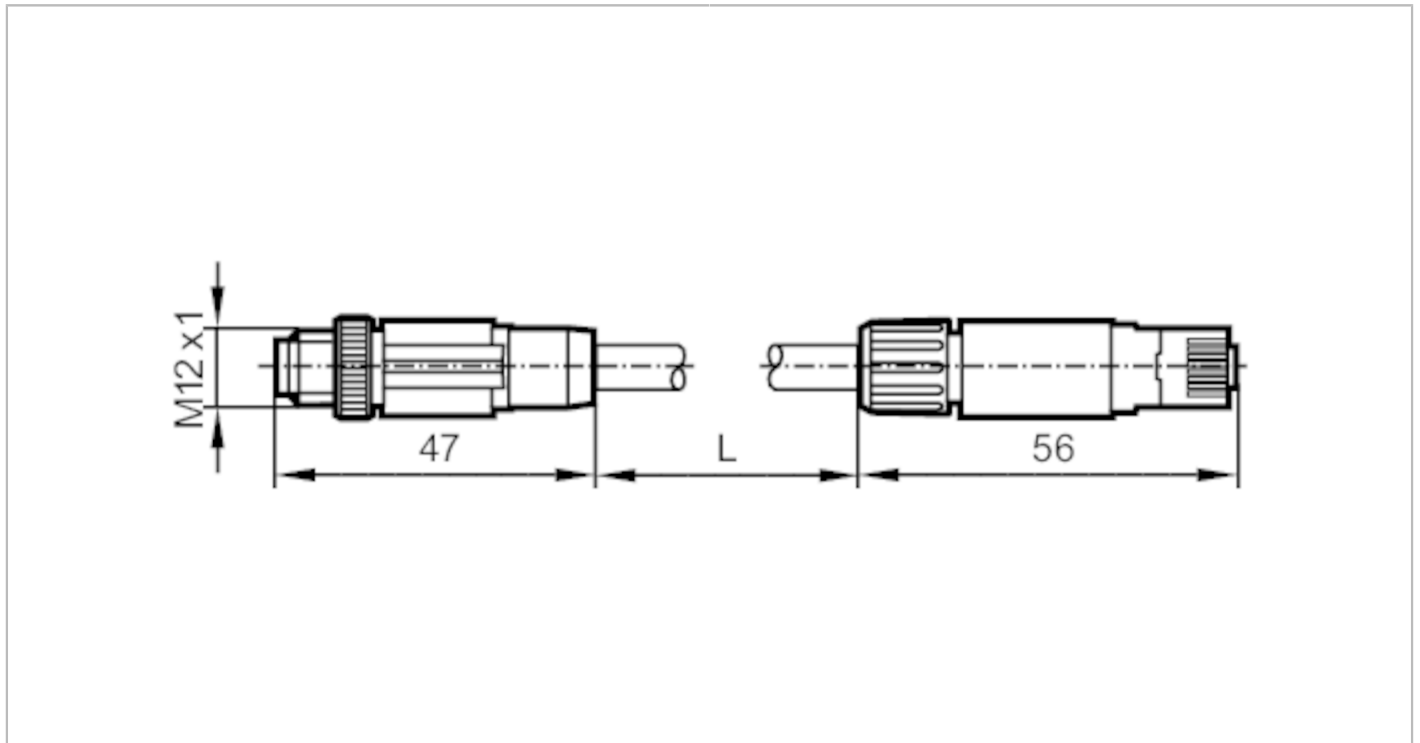

| Application                      |                                      |
|----------------------------------|--------------------------------------|
| Special feature                  | Screened cable                       |
| Design                           | Ethernet cable, D-coded              |
| Application                      | cross-over patch cable; patch cable  |
| Operating conditions             |                                      |
| Ambient temperature [°C]         | -25...70                             |
| Protection                       | IP 67; IP 20; (M12 plug / RJ45 plug) |
| Mechanical data                  |                                      |
| Weight [g]                       | 367.2                                |
| Materials                        | TPU / PA                             |
| Material nut                     | diecast zinc, nickel-plated          |
| Remarks                          |                                      |
| Pack quantity                    | 1 pcs.                               |
| Electrical connection - plug M12 |                                      |

Connector: 1 x M12, straight; Moulded body: PA; Locking: diecast zinc, nickel-plated; Tightening torque: 0.7...0.9 Nm



# E12491




## Connection cable

VSTGN040ZDS0005L04STGP080--S

### Electrical connection

Cable: 5 m, PVC, green, Ø 6.5 mm, shielded; 2 x 2 x 0.38 mm<sup>2</sup>

### Connection

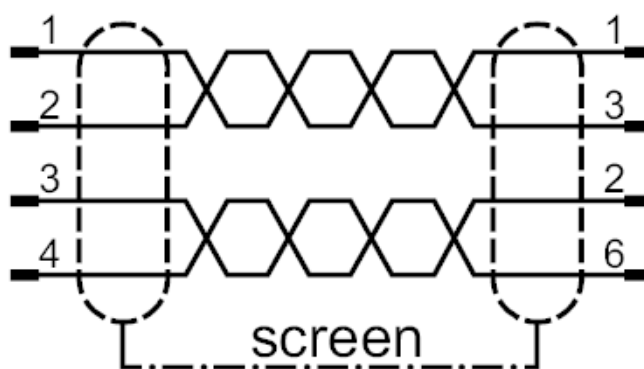

### Electrical connection - plug RJ45

Connector: 1 x RJ45, straight; Moulded body: TPU

