


E12495



Connecting cable with socket

ADOGD040ZDS0005H04

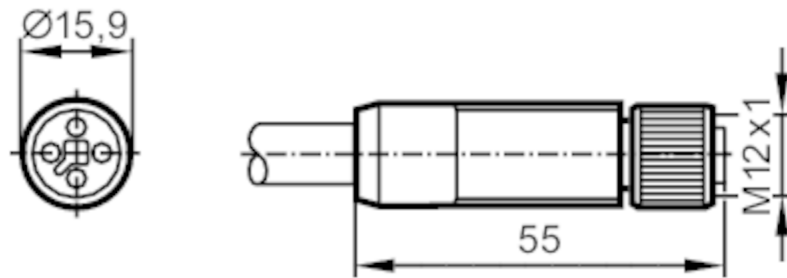


Application		
Special feature		Gold-plated contacts
Design		power cable, T-coded
Electrical data		
Operating voltage	[V]	< 60 AC
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 67
Mechanical data		
Weight	[g]	545
Dimensions	[mm]	15.4 x 15.4 x 52.8
Materials		PP
Material nut		diecast zinc, nickel-plated
Remarks		
Pack quantity		1 pcs.
Electrical connection		
Cable: 5 m, PUR, black, Ø 8 mm; 4 x 1.5 mm ²		
Electrical connection - socket		
Connector: 1 x M12, straight; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated		

E12495




Connecting cable with socket

ADOGD040ZDS0005H04

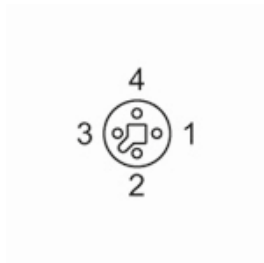

Connection

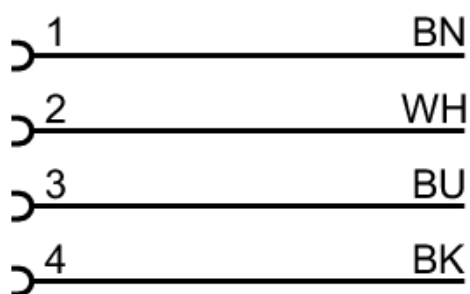

Core colours :

BK = black
BN = brown
BU = blue
WH = white