


E12679



Connection cable

VDOGS040--S0001H04DOGH040MSS

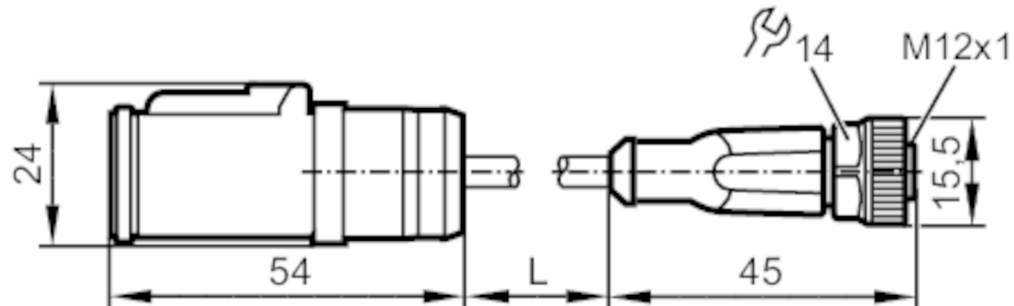

Application

Special feature	Free from silicone; Halogen-free; Drag chain suitability
Free from silicone	yes

Electrical data

Operating voltage [V]	8...32 DC
Protection class	III
Max. current load total [A]	4

Operating conditions

Ambient temperature [°C]	-40...80
Ambient temperature (moving) [°C]	-20...80
Protection	IP 67; (mating connector plugged in)

Mechanical data

Weight	[g]	94.3	
Materials		PA; socket: TPU orange; Sealing: FKM	
Material nut		brass, nickel-plated	
Drag chain suitability		yes	
Drag chain suitability		bending radius for flexible use	min. 10 x cable diameter
		travel speed	max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s²
		bending cycles	> 5 Mio.
		torsional strain	± 180 °/m

Remarks

Pack quantity	1 pcs.
---------------	--------

E12679



Connection cable

VDOGS040--S0001H04DOGH040MSS

Electrical connection - socket


Connector: 1 x DEUTSCH connector, straight



Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 5.4 mm; 4 x 0.50 mm² (28 x Ø 0.15 mm)

Connection

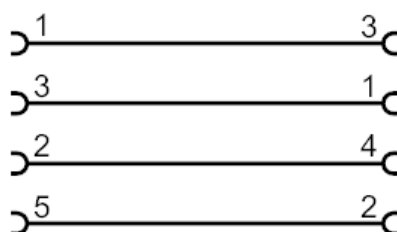

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Locking: brass, nickel-plated; Tightening torque: 0.6...1.5 Nm

