




Fibre optic through-beam sensor

FE-30-A-A-E3/2m

Article no longer available - archive entry

Alternative articles: E20347
When selecting an alternative article and accessories please note that technical data may differ!

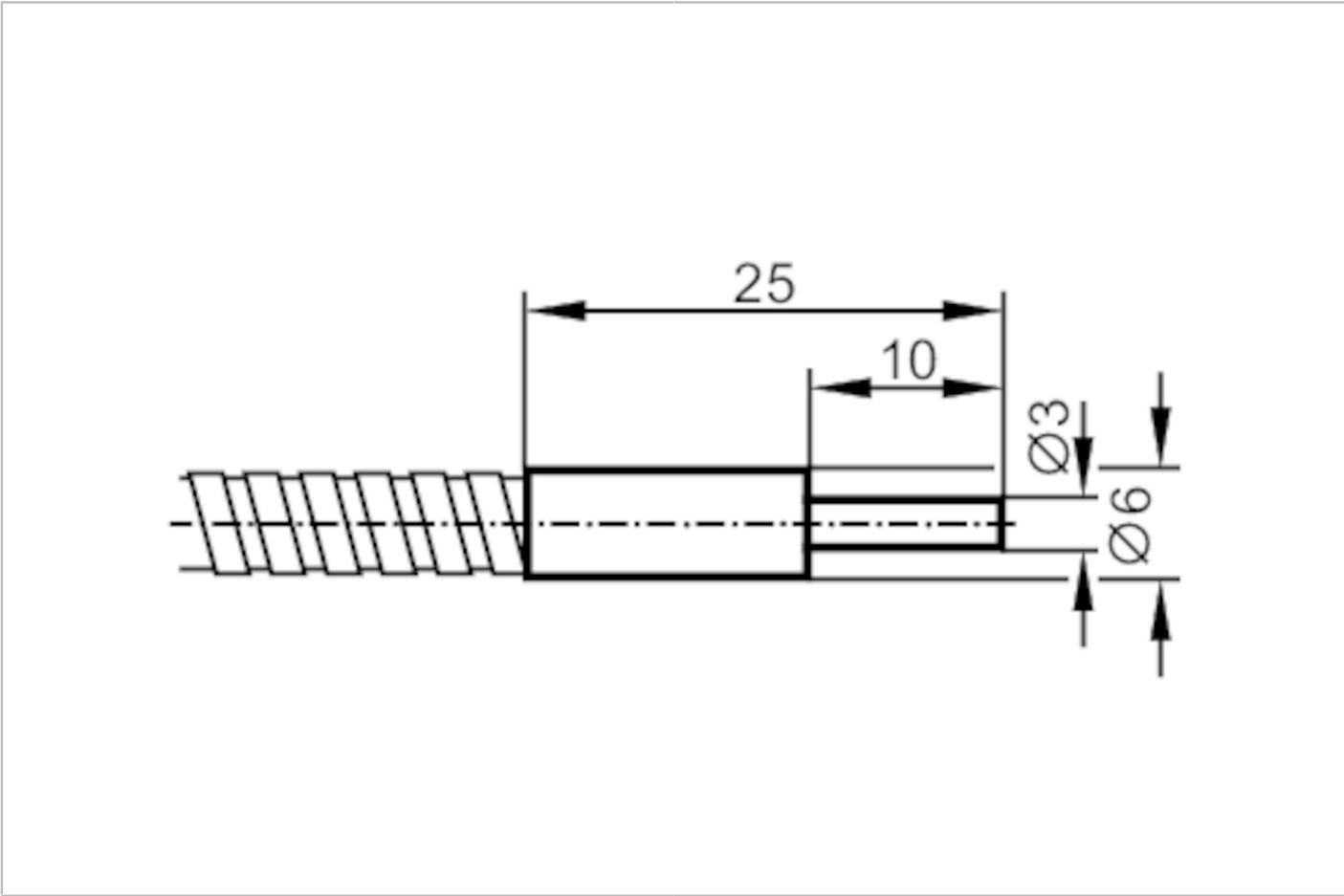

Application	
Function principle	Through-beam sensor
Detection zone	
Range with fibre-optic amplifier type	OIF
OIF	
Range of fibre optics [mm]	80
Operating conditions	
Ambient temperature [°C]	-40...290
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	3
Total length [mm]	2000
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium

E20346



Fibre optic through-beam sensor

FE-30-A-A-E3/2m

Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.