


Fibre optic diffuse reflection sensor

FT-00-A-A-R4/0,3M

Article no longer available - archive entry

Alternative articles: E20455

When selecting an alternative article and accessories please note that technical data may differ!

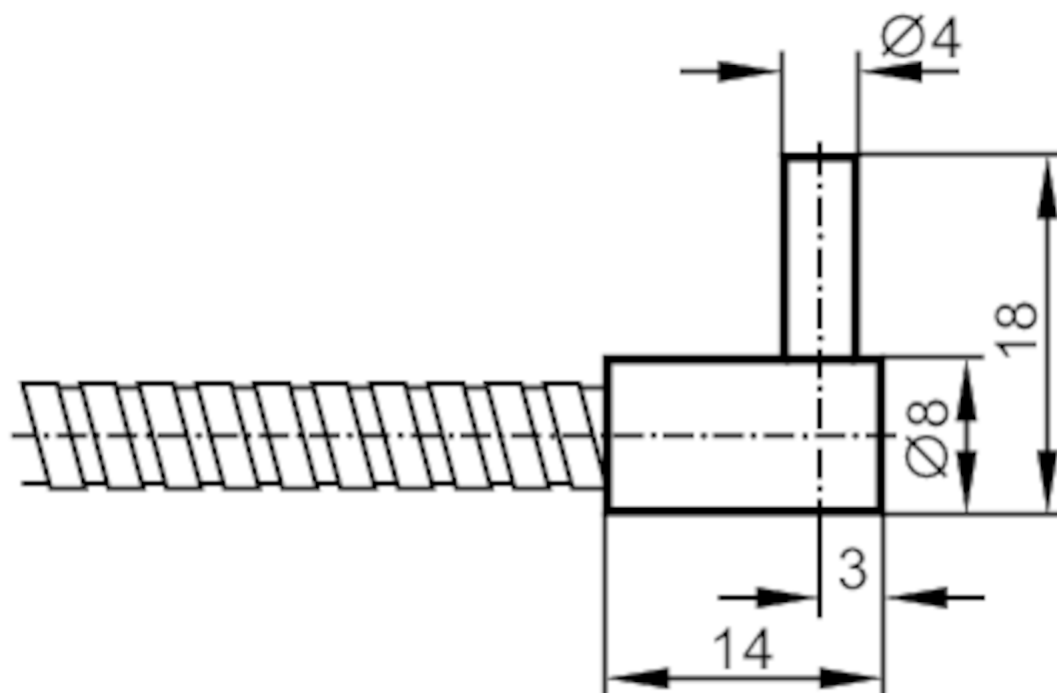

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

40

OUF

Range fibre optics

[mm]

40

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

angled

Sensing head diameter

[mm]

4

Sensing head length

[mm]

10

Total length

[mm]

300

E20377



Fibre optic diffuse reflection sensor

FT-00-A-A-R4/0,3M

Min. bending radius	[mm]	20
Materials	Adapter: ABS	
Fibre material	glass	
Fibre head material	aluminium	
Fibre sheath material	aluminium	
Remarks		
Pack quantity	1 pcs.	