


Fibre optic diffuse reflection sensor

FT-30-A-A-M8/1,5M

Article no longer available - archive entry

Alternative articles: E20137

When selecting an alternative article and accessories please note that technical data may differ!

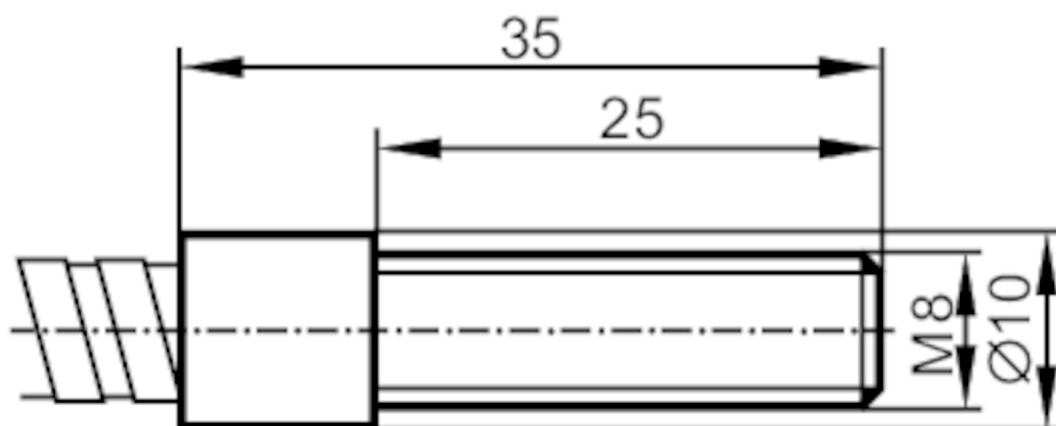

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OIF
---------------------------------------	-----

OIF

Range fibre optics [mm]	63
-------------------------	----

Operating conditions

Ambient temperature [°C]	-40...290
--------------------------	-----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M8
Total length [mm]	1500
Min. bending radius [mm]	30
Materials	Adapter: PA
Fibre material	glass
Fibre head material	aluminium

E20392



Fibre optic diffuse reflection sensor

FT-30-A-A-M8/1,5M

Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.