


# E2M251




## Adapter cables for cameras with video output

CONNECTION CABLE M16 8P 3,85M

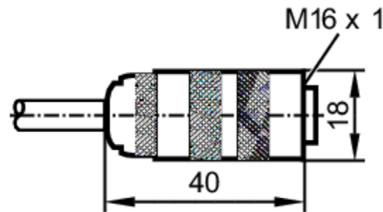

Application	
Special feature	Halogen-free; Drag chain suitability
Design	camera with video output O2M20x
Electrical data	
Operating voltage [V]	< 60 DC
Operating conditions	
Ambient temperature [°C]	-45...85
Protection	IP 67
Mechanical data	
Weight [g]	322.8
Materials	housing: diecast zinc; Sealing: PBT
Material nut	diecast zinc
Drag chain suitability	yes
Drag chain suitability	bending radius for fixed installation <span style="float: right;">≥ 100 mm</span>
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 3.85 m, PUR, Halogen-free, black, Ø 6 mm; 7 x 0.34 mm <sup>2</sup>	
Electrical connection - plug	
Connector: 1 x M16, straight; Locking: diecast zinc	

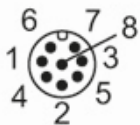

# E2M251



## Adapter cables for cameras with video output

CONNECTION CABLE M16 8P 3,85M

1	12 / 24 V DC red
2	GND white
3	IN 1 blue
4	IN 2 brown
5	IN 3 white/yellow
6	IN 4 grey
7	not used
8	not used