


E2D100



USB connection cable

ADAPTER CABLE M8 RS485-USB

Article no longer available - archive entry

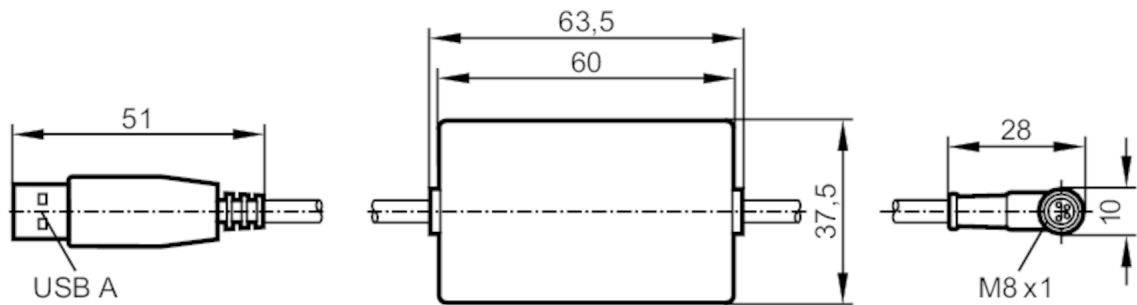

Application

Special feature

Halogen-free

Electrical data

Protection class

III

Operating conditions

Ambient temperature

[°C]

0...60

Protection

IP 54

Tests / approvals

EMC

EN 61000-6-1

Mechanical data

Materials

PUR

Moulded-body material

PUR

Material nut

brass, nickel-plated

Remarks

Pack quantity

1 pcs.

Electrical connection

Cable: 2 m, PUR, Halogen-free; 4 x 0.25 mm²


Electrical connection - Stecker



USB connection cable

ADAPTER CABLE M8 RS485-USB


Connection

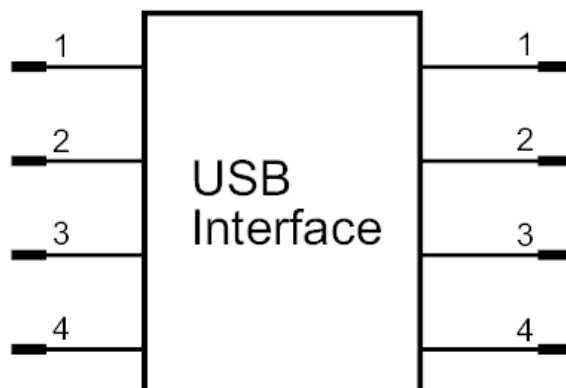

Electrical connection - plug

Connector: 1 x USB, straight; Moulded body: PUR; Locking: brass, nickel-plated

 Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated



Connection

