


## Wirable valve connector

VALVE PLUG TYPE A

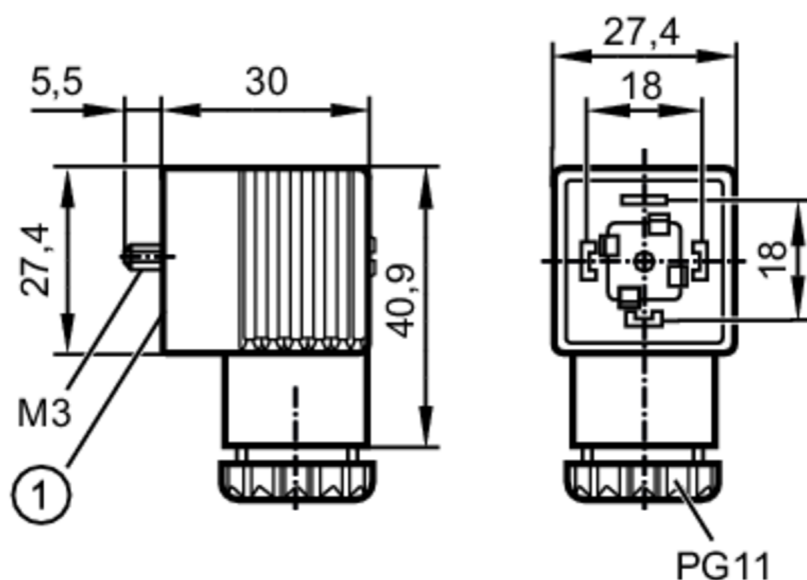

1 Sealing



## Application

|                    |                    |
|--------------------|--------------------|
| Special feature    | Free from silicone |
| Free from silicone | yes                |

## Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 45 AC / < 70 DC |
| Protection class        |     | III               |
| Max. current load total | [A] | 10                |

## Operating conditions

|                     |      |           |
|---------------------|------|-----------|
| Ambient temperature | [°C] | -40...125 |
| Protection          |      | IP 67     |

## Mechanical data

|                       |      |              |
|-----------------------|------|--------------|
| Weight                | [g]  | 32.3         |
| Dimensions            | [mm] | 41 x 27 x 30 |
| Materials             |      | PA; FKM      |
| Moulded-body material |      | PA           |

## Remarks

|               |  |        |
|---------------|--|--------|
| Pack quantity |  | 1 pcs. |
|---------------|--|--------|

# E30447




## Wirable valve connector


VALVE PLUG TYPE A

### Electrical connection

terminals: ...1.5 mm<sup>2</sup>; Cable sheath: Ø 6...8 mm

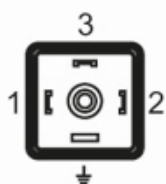

### Connection

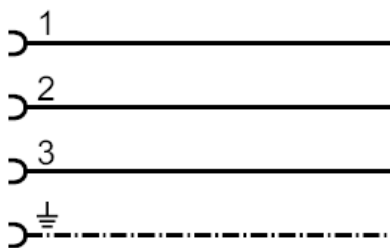

### Electrical connection - socket

Connector: 1 x valve plug type A DIN, angled; Moulded body: PA