


AS-Interface ClassicLine module

ClassicLine 4DI T M12 ATEX

Article no longer available - archive entry

Alternative articles: AC505A + E7000A

When selecting an alternative article and accessories please note that technical data may differ!

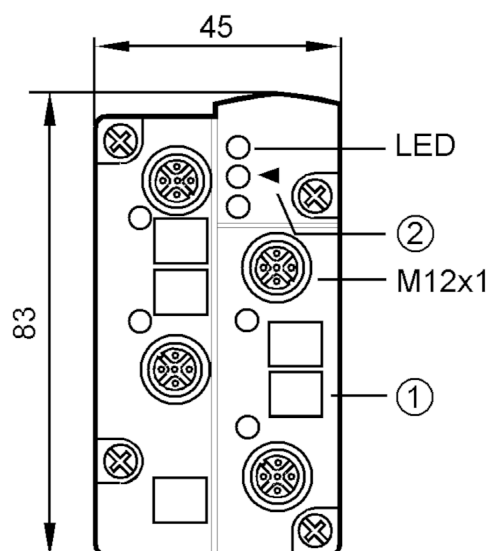

- 1 panel for labelling
2 fixture infrared adapter



Electrical data

Operating voltage	[V]	26.5...31.6 DC
Max. current consumption from AS-i	[mA]	240

Inputs / outputs

Number of inputs and outputs	Number of digital inputs: 4
------------------------------	-----------------------------

Inputs

Number of digital inputs		4
Input circuit of digital inputs		PNP
Sensor supply of the inputs		AS-i
Power supply	[V]	20...30
Max. total current rating of inputs	[mA]	200
Input current High	[mA]	6...10
Input current Low	[mA]	0...2
Switching level high	[V]	> 11
Digital inputs protected against short circuits		yes

ClassicLine 4DI T M12 ATEX

ifm electronic gmbh • Friedrichstraße 1 • 45128 Essen — EN-GB — AC005A — 08.12.2005 —

AC005A



AS-Interface ClassicLine module

ClassicLine 4DI T M12 ATEX

Electrical connection

Connector: M12; coding: A



	Inputs
1	Sensor supply L+
2+4	data input internally bridged
3	Sensor supply L-