


AC1146



AS-Interface diagnosis module

AS-i Tuner IP67

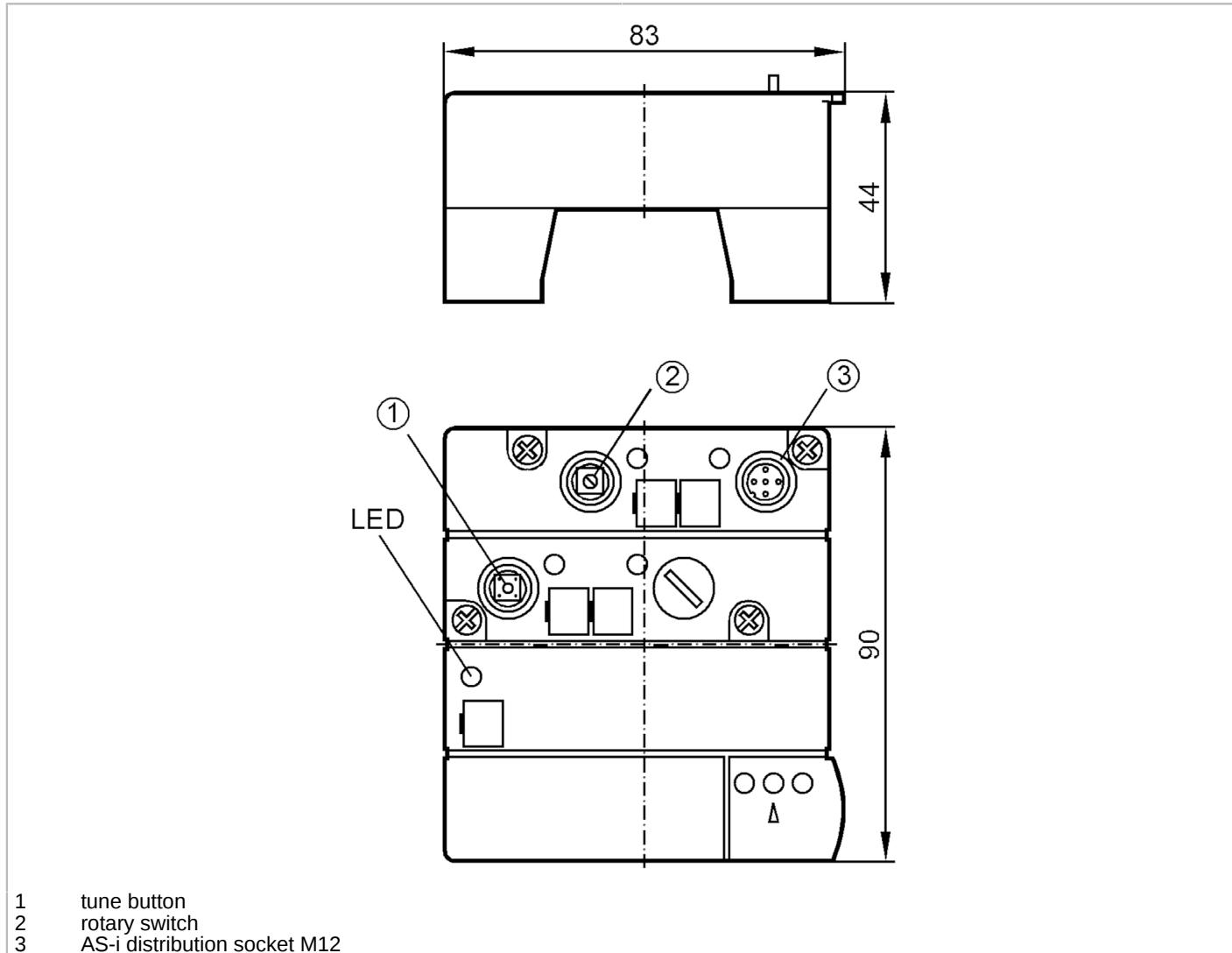

Application

Application	diagnostic tool for AS-i
-------------	--------------------------

Electrical data

Nominal voltage DC	[V]	26.5...31.6
--------------------	-----	-------------

Max. current consumption from AS-i	[mA]	60
------------------------------------	------	----

Reverse polarity protection	yes
-----------------------------	-----

Undervoltage monitoring	yes
-------------------------	-----

Operating conditions

Ambient temperature	[°C]	0...55
---------------------	------	--------

Protection	IP 67
------------	-------

Tests / approvals

MTTF	[years]	140
------	---------	-----

Mechanical data

Weight	[g]	199.2
--------	-----	-------

AC1146



AS-Interface diagnosis module

AS-i Tuner IP67

Materials

PBT

Displays / operating elements

Display	operation	LED, green
	warning	LED, yellow
	errors	LED, red

Accessories


Accessories (optional)	Module lower part:, AC5000
------------------------	----------------------------

Remarks

Remarks	no addressing required current rating of the AS-i distribution socket max. 1 A
Pack quantity	1 pcs.

Electrical connection

contact pins to module lower part, FK: Connector: M12; coding: A

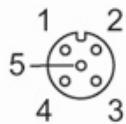

1	AS-i distribution socket M12 AS-i +
3	AS-i -