

E10409




Connecting cable with socket

ADOAH042MSS0005A03

Article no longer available - archive entry

Alternative articles: EVC008
When selecting an alternative article and accessories please note that technical data may differ!

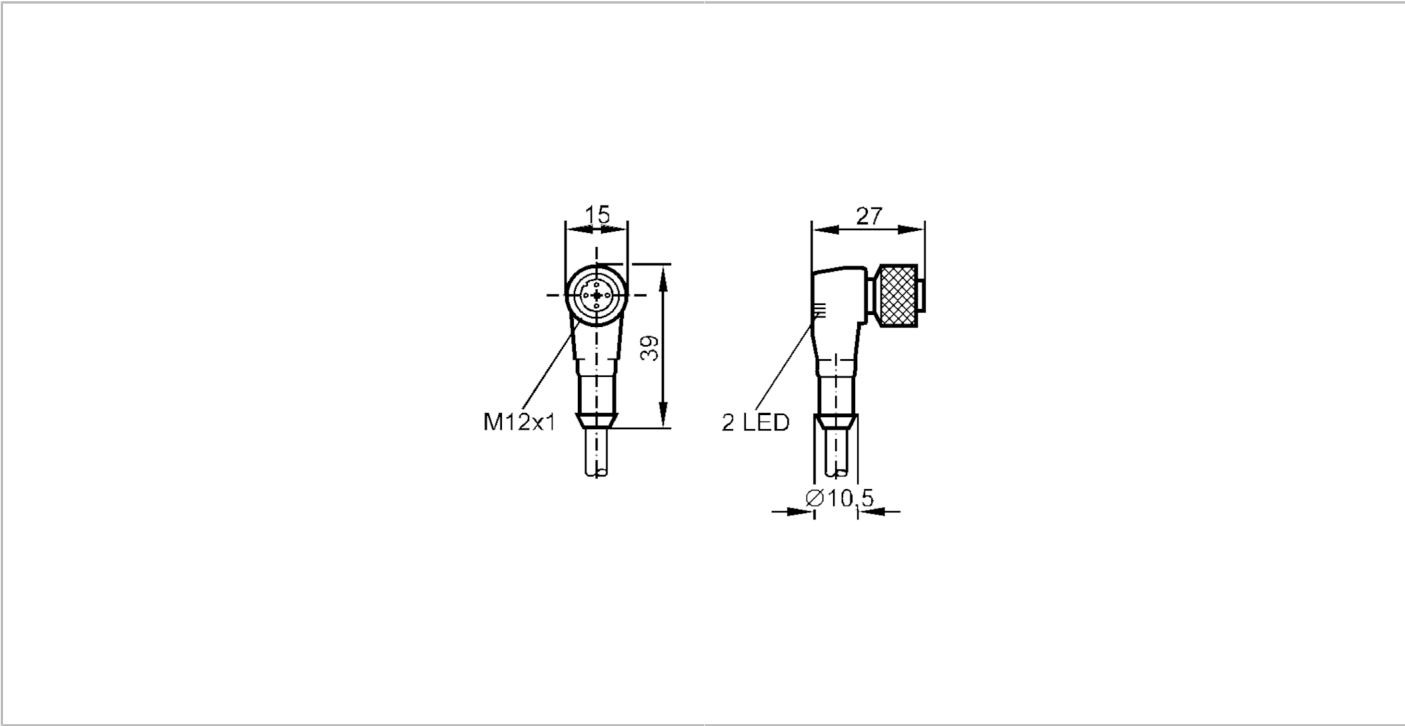

Electrical data		
Operating voltage	[V]	10...30 DC
Outputs		
Electrical design		PNP
Operating conditions		
Ambient temperature	[°C]	-25...90
Protection		IP 67
Mechanical data		
Weight	[g]	136.078
Dimensions	[mm]	27 x 15 x 39
Materials		TPU transparent
Moulded-body material		TPU, transparent
Material nut		brass, nickel-plated
Displays / operating elements		
Display	switching status	1 x LED, yellow
	operation	1 x LED, green
Remarks		
Pack quantity		1 pcs.

E10409



Connecting cable with socket

ADOAH042MSS0005A03

Electrical connection

Cable: 5 m, PUR / PVC, orange, Ø 5 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU, transparent; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Connection



BN =	Core colours :
BK =	brown
BU =	black
	blue