


# E10693



## Connection cable

VDOAH040MSS00,6B04STGH040MSS

Article no longer available - archive entry

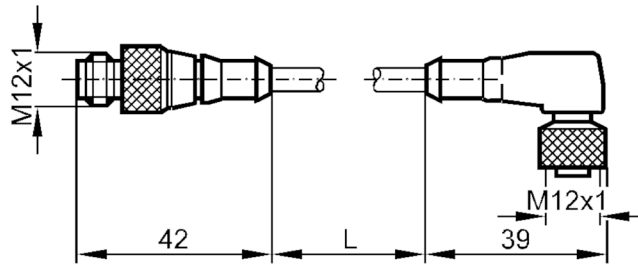

### Electrical data

Operating voltage [V] 10...30 DC

### Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

### Mechanical data

Materials PUR

Moulded-body material PUR

Material nut brass, nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated



# E10693




## Connection cable

VDOAH040MSS00,6B04STGH040MSS

### Electrical connection

Cable: 0.6 m, PUR; 4 x 0.25 mm<sup>2</sup> (128 x Ø 0.05 mm )

### Connection

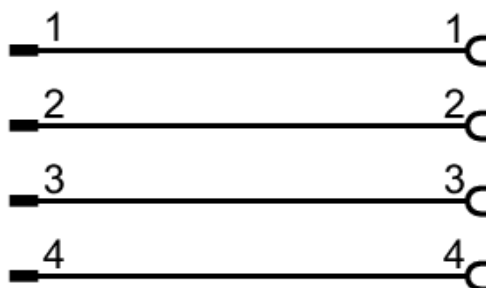

### Electrical connection - socket

Connector: 1 x M12, angled; Moulded body: PUR; Locking: brass, nickel-plated

