

# E10885




## Splitter box

ZDO4H050MSS0000-00STAK190MSS

Article no longer available - archive entry

Alternative articles: E11728

When selecting an alternative article and accessories please note that technical data may differ!

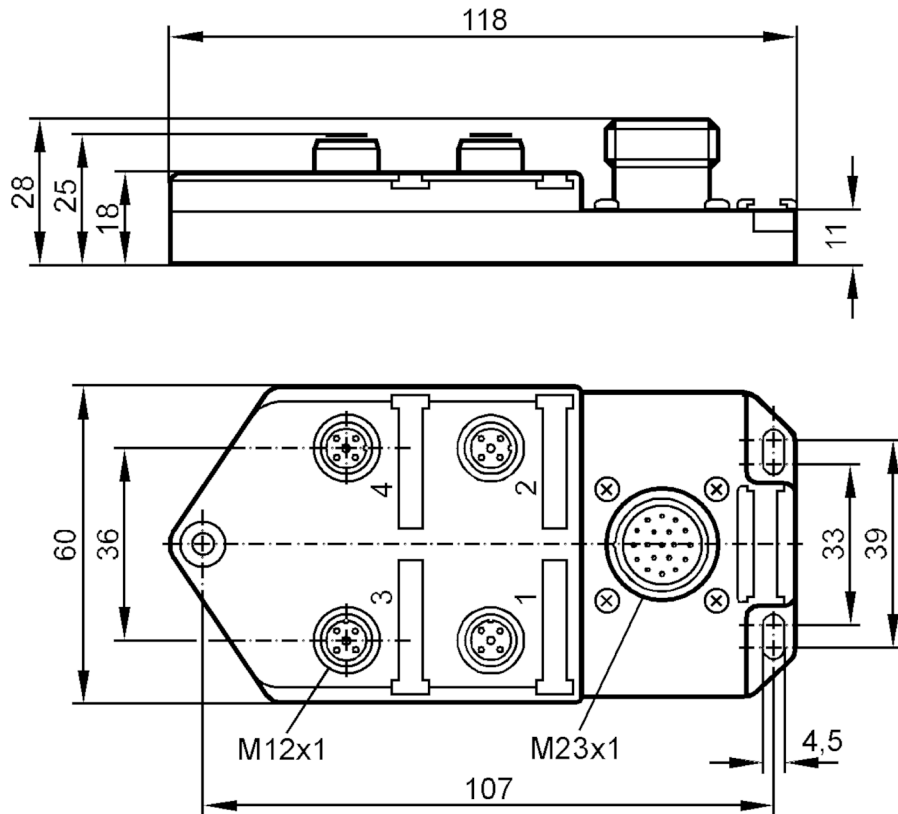

## Application

|                    |                                          |
|--------------------|------------------------------------------|
| Special feature    | Free from silicone; Gold-plated contacts |
| Free from silicone | yes                                      |

## Electrical data

|                                   |     |            |
|-----------------------------------|-----|------------|
| Operating voltage                 | [V] | 10...55 DC |
| Max. current load per module/slot | [A] | 4          |
| Max. current load total           | [A] | 12         |

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -15...90 |
| Protection          |      | IP 67    |

## Mechanical data

|                              |               |
|------------------------------|---------------|
| Dimensions [mm]              | 28 x 60 x 118 |
| Number of ports splitter box | 4             |
| Connector type               | M12           |

## Remarks

|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

# E10885




## Splitter box


ZDO4H050MSS0000-00STAK190MSS

### Electrical connection - Connection

Connector: 1 x M23; Contacts: gold-plated; Tightening torque: 0.5 Nm

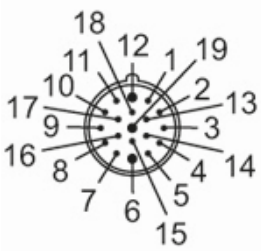

### Connection

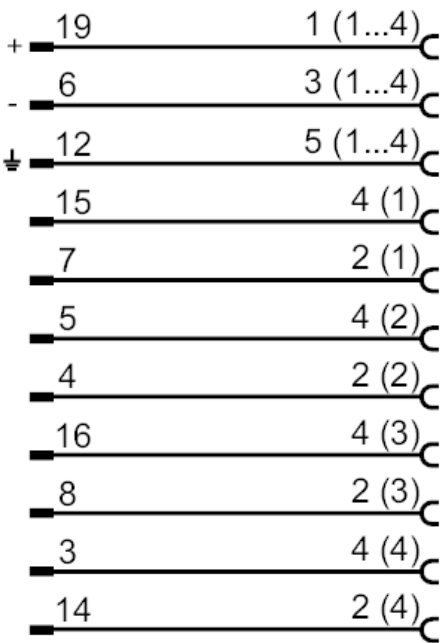

### Electrical connection - slot

Connector: 4 x M12; coding: A; Contacts: gold-plated; Tightening torque: 0.5 Nm

