

E10950




Connection cable

VDOGH040MSS0001H04STGH040MSS

Article no longer available - archive entry

Alternative articles: EVC012

When selecting an alternative article and accessories please note that technical data may differ!

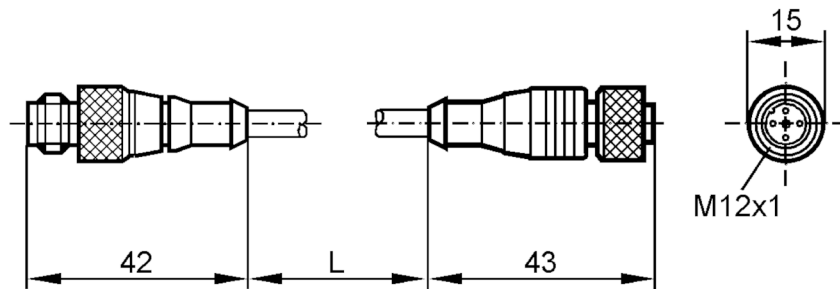

Application

Special feature Halogen-free

Electrical data

Operating voltage [V] < 250 AC / < 300 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 42

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

 
Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated

E10950



Connection cable


VDOGH040MSS0001H04STGH040MSS



Electrical connection

Cable: 1 m, PUR, Halogen-free; 4 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

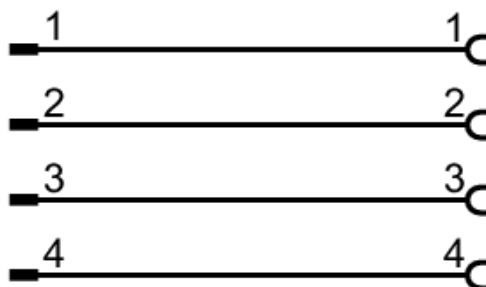

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated

