


E11437



Jumper cable with valve plug

VVSAC031MSS00,6H03STGH030MSS

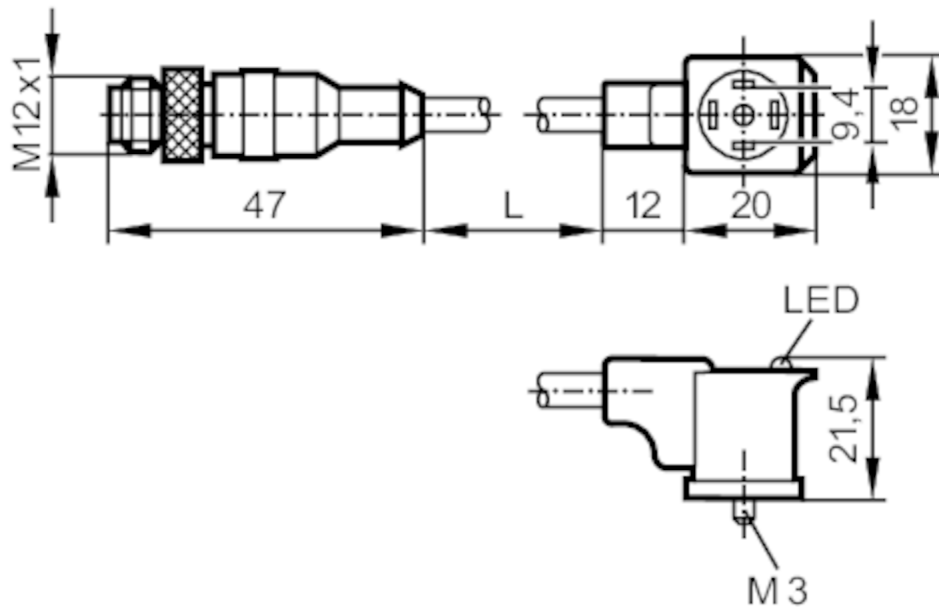

Application

Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage [V]	< 24 AC/DC
Overvoltage protection	yes; (VDR)
Max. current load total [A]	3

Operating conditions

Ambient temperature [°C]	-25...80
Protection	IP 67

Mechanical data

Weight [g]	59
Materials	PUR
Moulded-body material	PUR
Material nut	brass, nickel-plated

Displays / operating elements

Display	switching status	1 x LED, yellow
---------	------------------	-----------------

Accessories

Items supplied	screw
	panel for labelling

Remarks

Pack quantity	1 pcs.
---------------	--------

Jumper cable with valve plug

VVSAC031MSS00,6H03STGH030MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



Electrical connection

Cable: 0.6 m, PUR, Halogen-free, black, Ø 5 mm; 3 x 0.5 mm² (42 x Ø 0.1 mm)

Connection

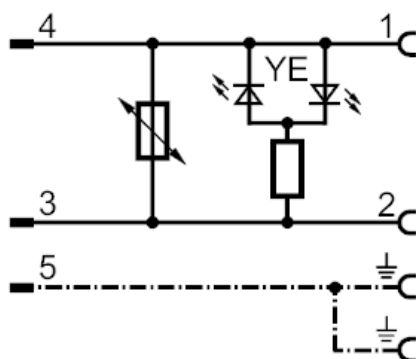

Electrical connection - socket

Connector: 1 x valve type C industrial standard, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: nickel-plated brass; Tightening torque: 0.7...0.9 Nm

