


E11448



Connection cable

VDOAF040MSS0001H04STGH040MSS

Article no longer available - archive entry

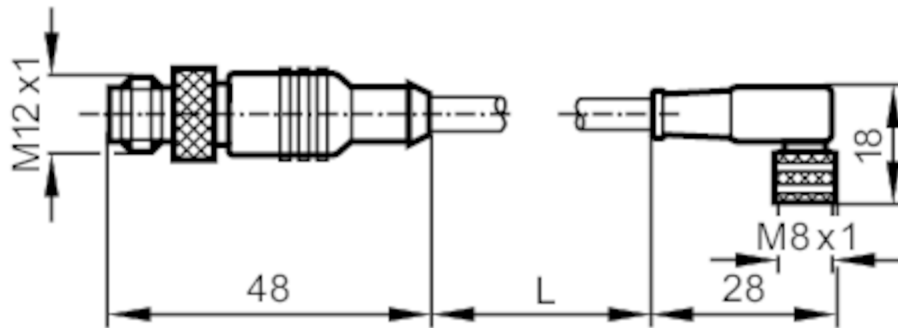

| Application | |
|-----------------------------|--|
| Special feature | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes |
| Electrical data | |
| Operating voltage [V] | < 60 AC / < 75 DC |
| Protection class | III |
| Max. current load total [A] | 3 |
| Operating conditions | |
| Ambient temperature [°C] | -25...85 |
| Protection | IP 68 |
| Mechanical data | |
| Materials | PUR |
| Moulded-body material | PUR |
| Material nut | brass, nickel-plated |
| Remarks | |
| Pack quantity | 1 pcs. |

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

E11448



Connection cable


VDOAF040MSS0001H04STGH040MSS



Electrical connection

Cable: 1 m, PUR, Halogen-free, black, Ø 4.4 mm; 4 x 0.25 mm² (32 x Ø 0.1 mm)

Connection

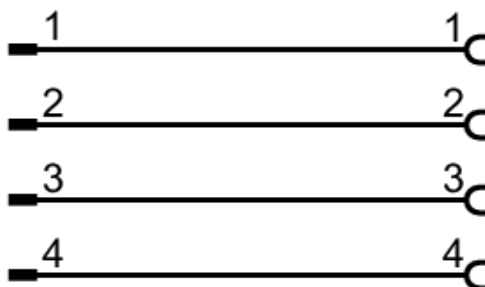

Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

