


## Connection cable

VDOAH050MSS0002H05STGH050MSS

Article no longer available - archive entry

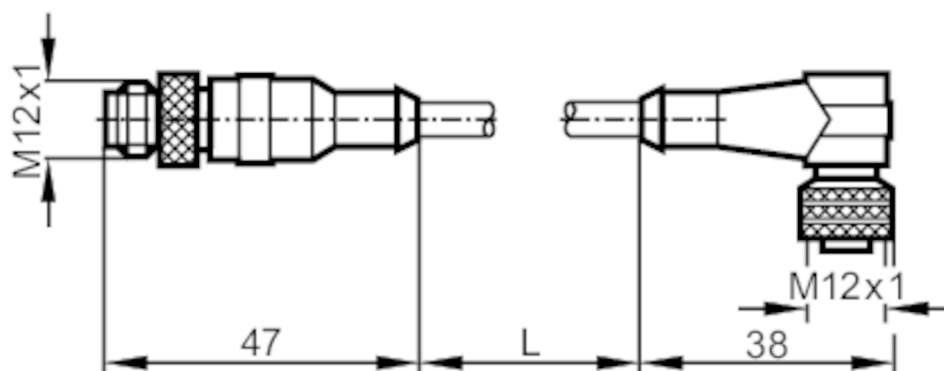

## Application

|                    |                                                        |
|--------------------|--------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts |
| Free from silicone | yes                                                    |

## Electrical data

|                         |     |                   |
|-------------------------|-----|-------------------|
| Operating voltage       | [V] | < 30 AC / < 36 DC |
| Max. current load total | [A] | 3                 |

## Operating conditions

|                     |      |          |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...85 |
| Protection          |      | IP 68    |

## Mechanical data

|                       |                      |
|-----------------------|----------------------|
| Materials             | PUR                  |
| Moulded-body material | PUR                  |
| Material nut          | brass, nickel-plated |

## Remarks


|               |        |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

## Connection cable

VDOAH050MSS0002H05STGH050MSS

### Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

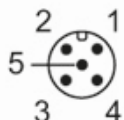

### Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 5 mm; 5 x 0.34 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

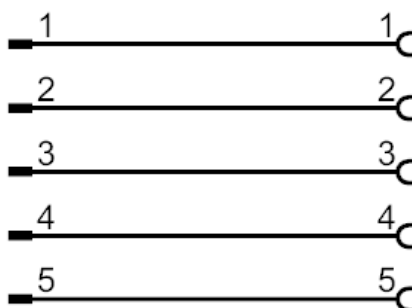

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

