

E11500



Connecting cable with socket

ADOAF030VAS0025E03

Article no longer available - archive entry



Application	
Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 60 AC / < 75 DC
Protection class	III
Operating conditions	
Ambient temperature [°C]	-25...85
Protection	IP 68
Mechanical data	
Materials	PVC
Moulded-body material	PVC
Material nut	stainless steel (1.4404 / 316L)
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 25 m, PVC, orange, Ø 5 mm; 3 x 0.25 mm ² (32 x 0.1 mm)	
Electrical connection - socket	
Connector: 1 x M8, angled; Moulded body: PVC; Locking: stainless steel (1.4404 / 316L); Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm	

E11500




Connecting cable with socket

ADOAF030VAS0025E03



Connection

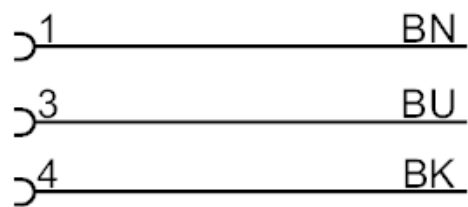

Core colours :

BK = black
BN = brown
BU = blue