

E11734




Splitter box

ZDO8H050MSS0000-00STAK190MSS

Article no longer available - archive entry

Alternative articles: EBC011
When selecting an alternative article and accessories please note that technical data may differ!

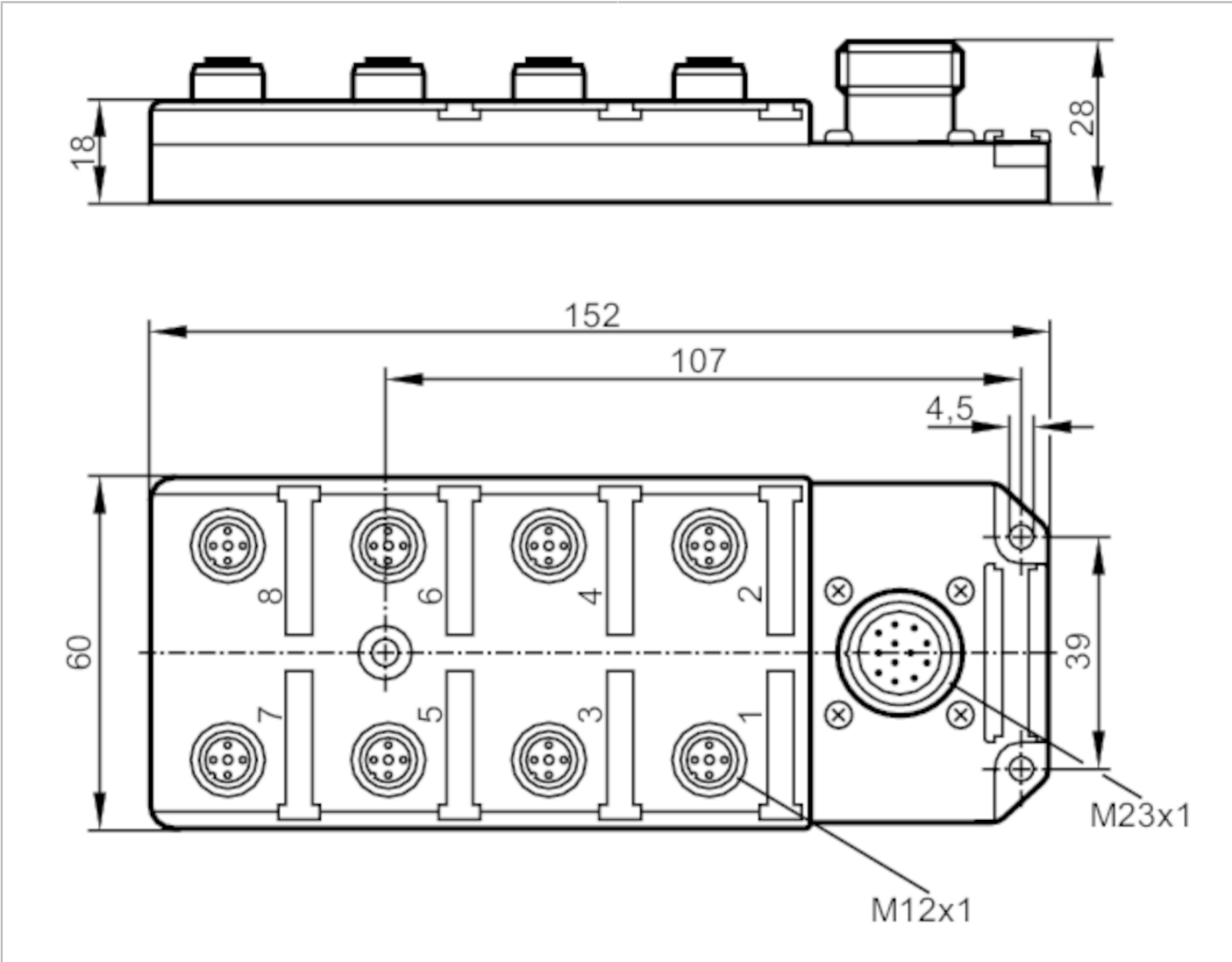

Application		
Special feature		Free from silicone; Gold-plated contacts
Free from silicone		yes
Electrical data		
Operating voltage	[V]	< 60 AC / < 75 DC
Protection class		II
Max. current load per module/slot	[A]	4
Max. current load total	[A]	10
Operating conditions		
Ambient temperature	[°C]	-15...80
Protection		IP 67

E11734



Splitter box


ZDO8H050MSS0000-00STAK190MSS

Mechanical data		
Dimensions	[mm]	28 x 60 x 152
Materials		TPU
Moulded-body material		TPU
Number of ports splitter box		8
Connector type		M12

Remarks	
Pack quantity	1 pcs.

Electrical connection - Connection

Connector: 1 x M23; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

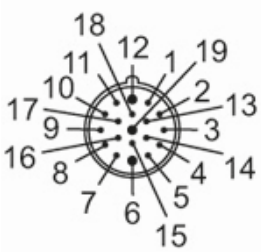

Connection

+	19	1 (1...8)
-	6	3 (1...8)
±	12	5 (1...8)
	15	4 (1)
	7	2 (1)
	5	4 (2)
	4	2 (2)
	16	4 (3)
	8	2 (3)
	3	4 (4)
	14	2 (4)
	17	4 (5)
	9	2 (5)
	2	4 (6)
	13	2 (6)
	11	4 (7)
	10	2 (7)
	1	4 (8)
	18	2 (8)

E11734



Splitter box

ZDO8H050MSS0000-00STAK190MSS

Electrical connection - slot

Connector: 8 x M12; coding: A; Moulded body: TPU; Contacts: gold-plated; Tightening torque: 0.5 Nm

