


Connection cable

VDOAH043MSS0002H04STGH040MSS

Article no longer available - archive entry

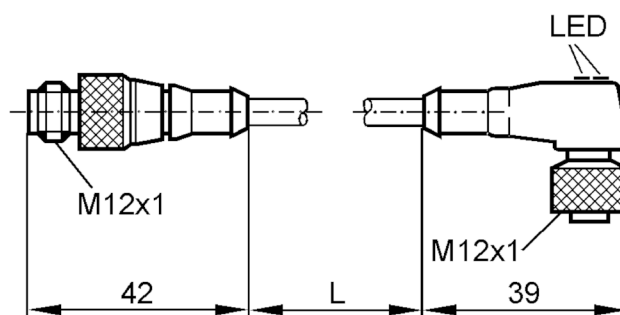

Application

Special feature	Halogen-free
-----------------	--------------

Electrical data

Operating voltage	[V]	10...30 DC
-------------------	-----	------------

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Materials	TPU
Moulded-body material	TPU
Material nut	brass, nickel-plated

Displays / operating elements

Display	switching status	2 x LED, yellow
	operation	1 x LED, green

Remarks

Pack quantity	1 pcs.
---------------	--------



Connection cable

VDOAH043MSS0002H04STGH040MSS

Electrical connection - plug


Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm



Electrical connection

Cable: 2 m, PUR, Halogen-free, black, Ø 4.7 mm; 4 x 0.34 mm²

Connection

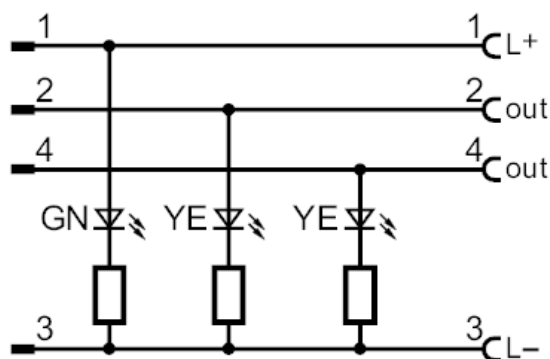

Core colours :
 BK = black
 BN = brown
 BU = blue
 WH = white

Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.5 Nm

