


E11315



Adapter plug

ESTGH050MSS00,5E05 (M20)

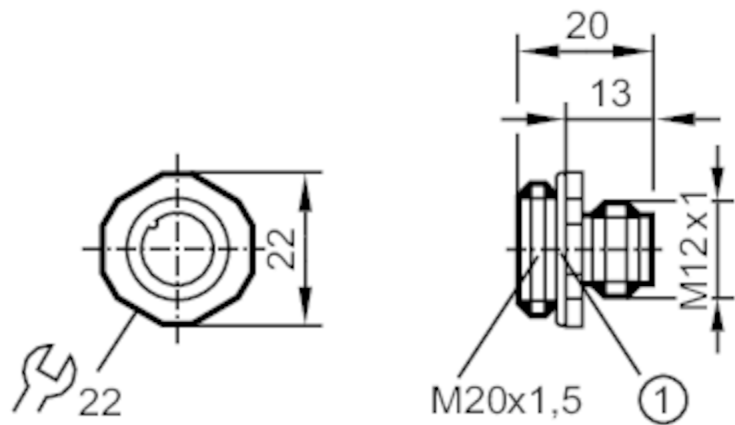

Electrical data		
Operating voltage	[V]	< 125 AC/DC
Operating conditions		
Ambient temperature	[°C]	-25...85
Protection		IP 68
Mechanical data		
Weight	[g]	27.3
Dimensions	[mm]	18 x 18 x 19
Mounting thread		M20
Materials		brass nickel-plated
Moulded-body material		brass, nickel-plated
Remarks		
Pack quantity		1 pcs.

E11315



Adapter plug


ESTGH050MSS00,5E05 (M20)

Electrical connection

Cable: 0.5 m, PVC; 4 x 0.25 mm² + 1 x 0.5 mm²

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: brass, nickel-plated; Tightening torque: ...0.6 Nm; thread M20 Tightening torque: ...2 Nm

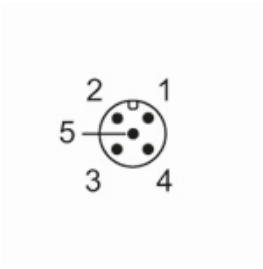

Connection

1	BN
2	WH
3	BU
4	BK
5	GN/YE

	Core colours :
BK =	black
BN =	brown
BU =	blue
GN =	green
WH =	white
YE =	yellow