

# E11318




## Connection cable

VDOGF030MSS0005B03STGF030MSS

Article no longer available - archive entry

Alternative article: E11353 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!

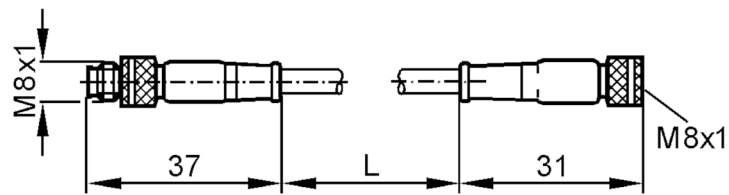

### Electrical data

Operating voltage	[V]	10...30 DC
Protection class		III

### Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 68

### Mechanical data

Materials	TPU
Material nut	brass, nickel-plated / brass, nickel-plated

### Remarks

Pack quantity	1 pcs.
---------------	--------

### Electrical connection - plug

Connector: 1 x M8, straight; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.6...0.7 Nm



# E11318




## Connection cable

VDOGF030MSS0005B03STGF030MSS

### Electrical connection


Cable: 5 m, TPU, black, Ø 4.5 mm; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

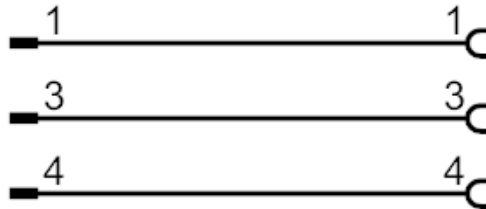

### Electrical connection - socket

 Connector: 1 x M8, straight; Moulded body: TPU; Locking: brass, nickel-plated; Tightening torque: 0.6...0.7 Nm



Article no longer available - archive entry

Alternative article: E11353 When selecting an alternative article and accessories please note that technical data may differ! – When selecting an alternative article and accessories please note that technical data may differ!