

# E11353




## Connection cable

VDOGF030MSS0005H03STGF040MSS

Article no longer available - archive entry

replaced by: EVC309

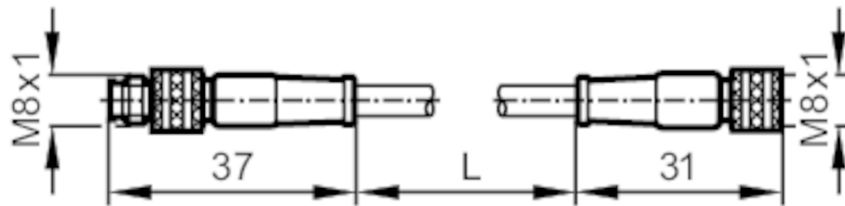

### Application

Free from silicone  yes

### Electrical data

Operating voltage [V] < 60 AC / < 75 DC

Protection class III

Max. current load total [A] 3

### Operating conditions

Ambient temperature [°C] -25...85

Protection IP 68

### Mechanical data

Materials PUR

Material nut brass, nickel-plated / brass, nickel-plated

### Remarks

Pack quantity 1 pcs.

### Electrical connection - plug

Connector: 1 x M8, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm

# E11353



## Connection cable


VDOGF030MSS0005H03STGF040MSS



### Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.1 mm; 3 x 0.25 mm<sup>2</sup> (32 x Ø 0.1 mm )

### Connection

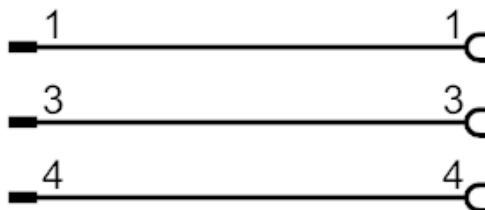

### Electrical connection - socket

Connector: 1 x M8, straight; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...0.7 Nm



Article no longer available - archive entry

replaced by: EVC309