


Y-splitter

Y-Splitter M12/2xM12 DO/ST

Article no longer available - archive entry

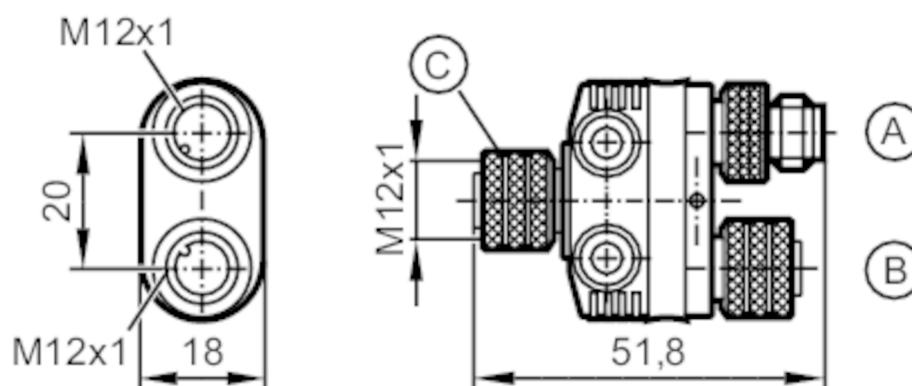

Application

Special feature	Free from silicone; Gold-plated contacts
Free from silicone	yes

Electrical data

Operating voltage	[V]	< 250 AC/DC
Max. current load per module/slot	[A]	4
Max. current load total	[A]	4

Operating conditions

Ambient temperature	[°C]	-25...90
Protection		IP 67

Mechanical data

Weight	[g]	29.6
Materials		PUR
Moulded-body material		PUR
Material nut		brass, nickel-plated

Remarks


Pack quantity	1 pcs.
---------------	--------

Y-splitter

Y-Splitter M12/2xM12 DO/ST

Electrical connection

Connection

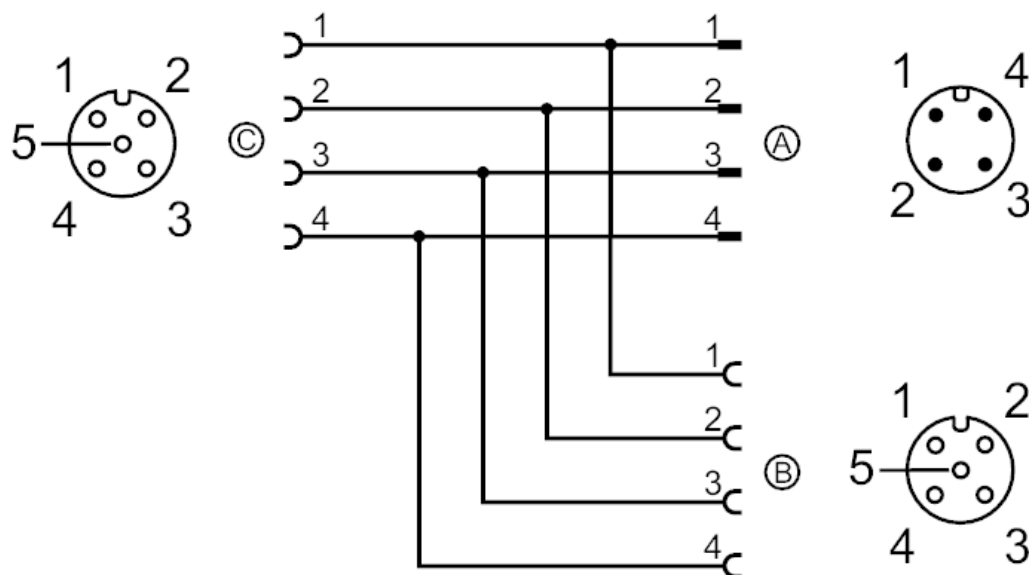

Electrical connection - plug

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

Electrical connection - socket

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated

Connector: 1 x M12; Moulded body: PUR; Locking: brass, nickel-plated; Contacts: gold-plated