


E18001



Connecting cable with socket

ADOGH040MKS0010X04

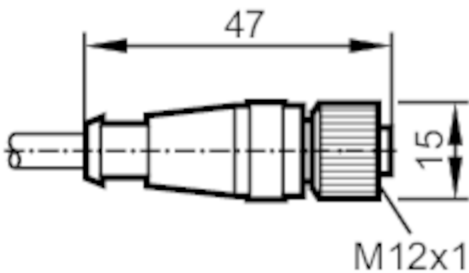

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 300 AC/DC
Operating conditions		
Ambient temperature	[°C]	-45...105
Protection		IP 68
Mechanical data		
Weight	[g]	361.966
Dimensions	[mm]	15 x 15 x 47
Materials		TPE
Moulded-body material		TPE
Material nut		zinc, epoxy coated
Remarks		
Pack quantity		1 pcs.

E18001



Connecting cable with socket

ADOGH040MKS0010X04

Electrical connection


Cable: 10 m, TPE-S, black; 4 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: TPE; Locking: zinc, epoxy coated; Contacts: gold-plated



Connection

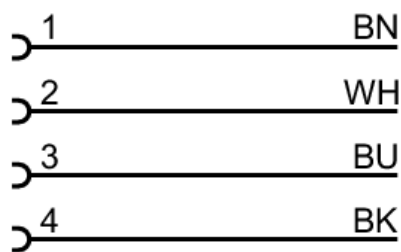

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white