


E18051



Connecting cable with socket

ADOGH040VAS0015E04

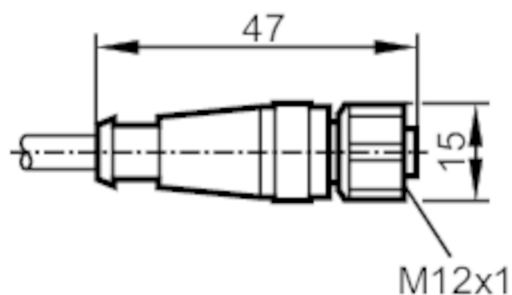

Application

Special feature	Gold-plated contacts
-----------------	----------------------

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	544.31
Dimensions	[mm]	15 x 15 x 47
Materials		PVC
Moulded-body material		PVC
Material nut		stainless steel (316Ti/1.4571)

Remarks

Pack quantity	1 pcs.
---------------	--------

E18051



Connecting cable with socket

ADOGH040VAS0015E04

Electrical connection

Cable: 15 m, PVC, grey; 4 x 0.34 mm² / AWG 22

Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated



Connection



5: not used
Core colours :
BK = black
BN = brown
BU = blue
WH = white