




## Connecting cable with socket

ADOGH040VAS0025E04

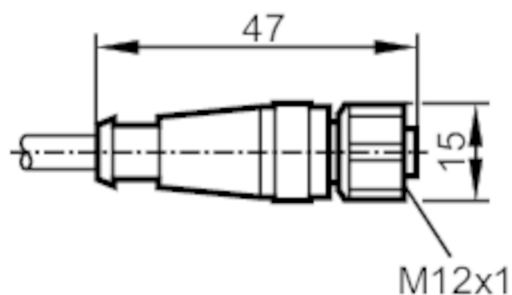

| Application              |                                |
|--------------------------|--------------------------------|
| Special feature          | Gold-plated contacts           |
| Electrical data          |                                |
| Operating voltage [V]    | < 300 AC/DC                    |
| Operating conditions     |                                |
| Ambient temperature [°C] | -20...105                      |
| Protection               | IP 68                          |
| Mechanical data          |                                |
| Weight [g]               | 874.979                        |
| Dimensions [mm]          | 15 x 15 x 47                   |
| Materials                | PVC                            |
| Moulded-body material    | PVC                            |
| Material nut             | stainless steel (316Ti/1.4571) |
| Remarks                  |                                |
| Pack quantity            | 1 pcs.                         |

# E18091



## Connecting cable with socket


ADOGH040VAS0025E04

### Electrical connection


Cable: 25 m, PVC, grey, Ø 5 mm; 4 x 0.34 mm² / AWG 22

### Electrical connection - socket

Connector: 1 x M12, straight; coding: A; Moulded body: PVC; Locking: stainless steel (316Ti/1.4571); Contacts: gold-plated

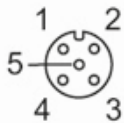

### Connection

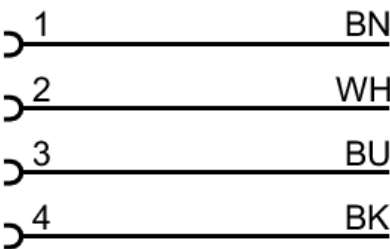

5: not used  
Core colours :  
BK = black  
BN = brown  
BU = blue  
WH = white