


Fibre optic diffuse reflection sensor

FT-00-A-A-M6/2,1m

Article no longer available - archive entry

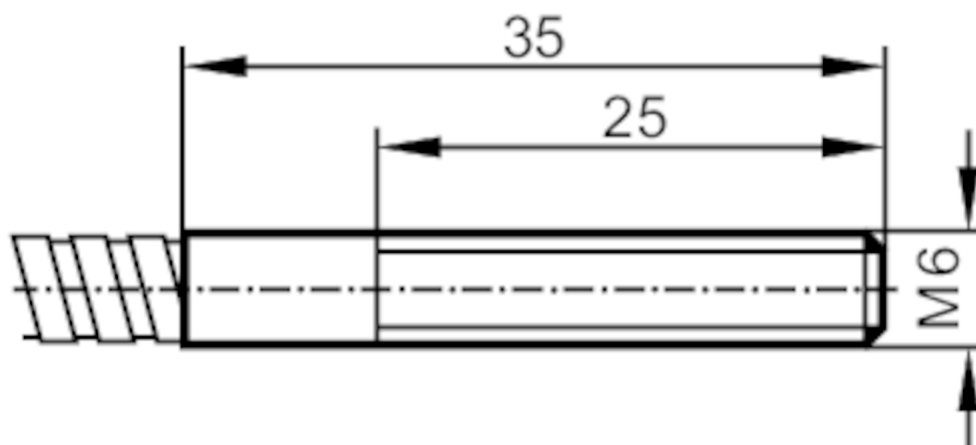

Application

Function principle

Diffuse reflection sensor

Detection zone

Range with fibre optic amplifier type

OKF; OUF

OKF

Range fibre optics

[mm]

30

OUF

Range fibre optics

[mm]

30

Operating conditions

Ambient temperature

[°C]

-40...290

Mechanical data

Version of sensing head

straight

Sensing head thread

M6

Sensing head length

[mm]

35

Total length

[mm]

600

Min. bending radius

[mm]

20

Materials

Adapter: ABS

Fibre material

glass

E20257



Fibre optic diffuse reflection sensor

FT-00-A-A-M6/2,1m

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.