


Fibre optic diffuse reflection sensor

FT-00-A-A-M6/S 1,3m lang

Article no longer available - archive entry

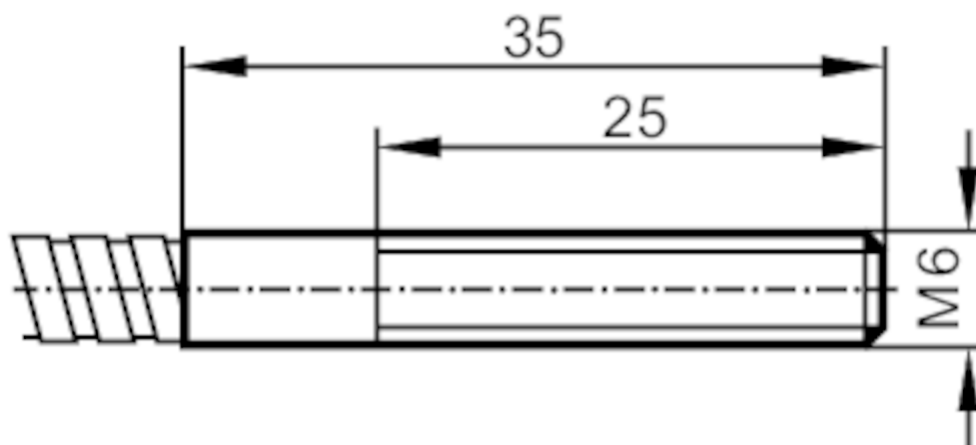

Application

Function principle	Diffuse reflection sensor
--------------------	---------------------------

Detection zone

Range with fibre optic amplifier type	OKF; OUF
---------------------------------------	----------

OKF

Range fibre optics [mm]	40
-------------------------	----

OUF

Range fibre optics [mm]	40
-------------------------	----

Operating conditions

Ambient temperature [°C]	-40...350
--------------------------	-----------

Mechanical data

Version of sensing head	straight
Sensing head thread	M6
Sensing head length [mm]	35
Total length [mm]	1300
Min. bending radius [mm]	20
Materials	Adapter: ABS
Fibre material	glass

E20264



Fibre optic diffuse reflection sensor

FT-00-A-A-M6/S 1,3m lang

Fibre head material	aluminium
Fibre sheath material	aluminium
Remarks	
Pack quantity	1 pcs.