


# E21138



## Ethernet connection cable

VSTGN040ZDS0002L04STGN04ZDS

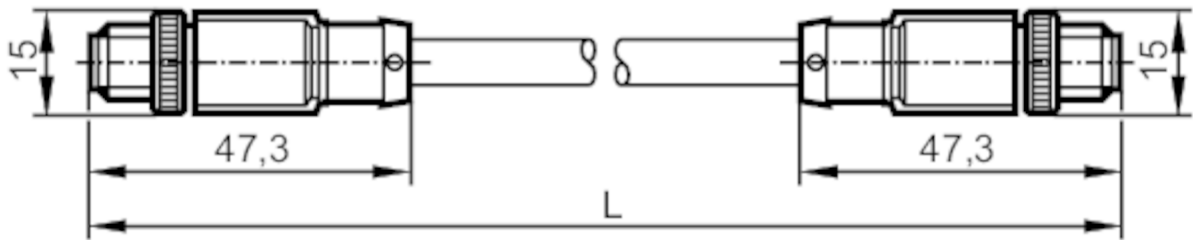

Application	
Special feature	Gold-plated contacts; Screened cable
Design	Ethernet cable, D-coded
Electrical data	
Operating voltage [V]	< 50 AC / < 60 DC
Protection class	III
Max. current load total [A]	4
Operating conditions	
Ambient temperature [°C]	-20...90
Protection	IP 67
Mechanical data	
Weight [g]	163.5
Dimensions [mm]	15 x 15 x 47.3
Materials	TPU
Material nut	diecast zinc, nickel-plated / diecast zinc, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection - plug	
Connector: 1 x M12, straight; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected	

# E21138



## Ethernet connection cable


VSTGN040ZDS0002L04STGN04ZDS



### Electrical connection

Cable: 2 m, PVC, green, shielded; 4 x 0.34 mm<sup>2</sup>

### Connection

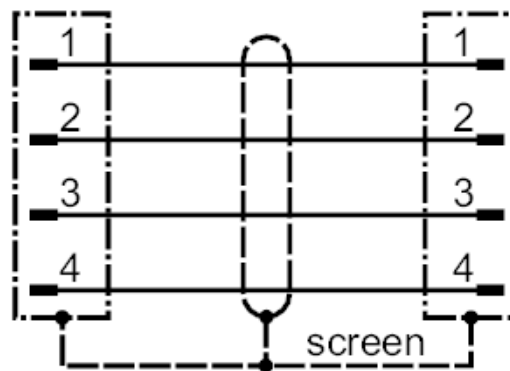

### Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: diecast zinc, nickel-plated; Contacts: gold-plated; Shielded connection cable: screen connected

