




## Process adapter Tri-Clamp

ADA IFM-CLAMP ISO2852 1.5" 3A

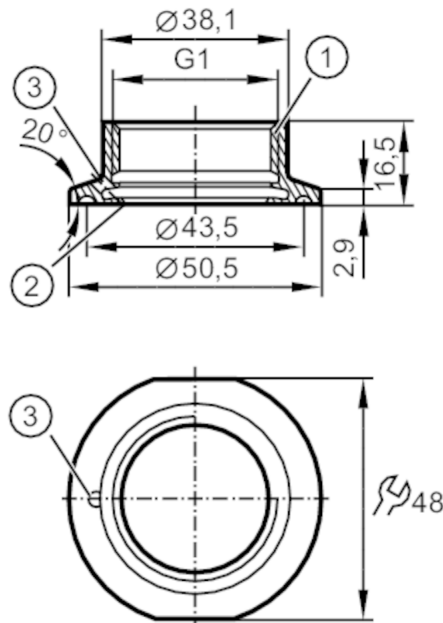

- 1 Aseptoflex Vario
- 2 sealing area
- 3 Leakage port



CRN EC 1935/2004 EHEDG Certified



| Application                           |   |
|---------------------------------------|---|
| Design                                | with leakage port   |
| Pressure rating [bar]                 | 16  |
| Tests / approvals                     |   |
| Pressure Equipment Directive          | A possible classification to PED depends on the application and has to be carried out by the user / operator. |
| Safety instructions                   | The compatibility between medium and product material has to be checked in all applications.                  |
| Mechanical data                       |   |
| Weight [g]                            | 100   |
| Materials (wetted parts)              | stainless steel (1.4435 / 316L) ; surface characteristics : Ra<0,4 / Rz 4                                     |
| Sensor connection                     | G 1 internal thread Aseptoflex Vario  |
| Process connection                    | Clamp DN25...DN40 (1...1,5") DIN 32676 (ISO 2852)   |
| Sealing                               | Gasket  |
| Hygienic equipment class to DIN 11866 | H4  |
| Accessories                           |   |
| Items supplied                        | O-ring: 1 x 24 x 2, EPDM, FDA compliant, E30054   |
| Accessories (optional)                | O-ring: 1 x 24 x 2, FKM, FDA compliant, E30123  |
|                                       | sealing ring: 1, PEEK, FDA compliant, E30124  |
| Remarks                               |   |
| Pack quantity                         | 1 pcs.  |