


E60123



Wirable plug

SSTGK120MKRFKSG

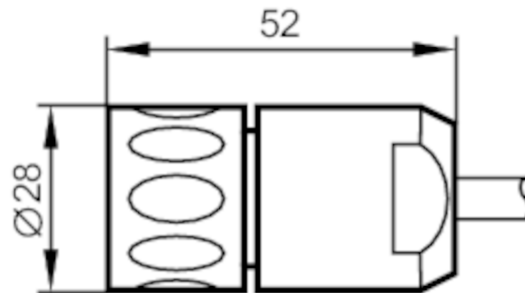

Electrical data

Operating voltage [V] 4.5...30 DC

Operating conditions

Ambient temperature [°C] -40...125

Protection IP 67

Mechanical data

Weight [g] 44.8

Dimensions [mm] 28 x 28 x 52

Materials brass in plastic sheath; PA 6.6 black

Material nut brass, in plastic sheath / PA 6.6, in plastic sheath

Remarks

Pack quantity 1 pcs.


Electrical connection

soldering: ...1 mm²

Electrical connection - plug

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: brass, in plastic sheath

Connector: 1 x M23, straight; Moulded body: brass / PA 6.6, in plastic sheath; Locking: PA 6.6, in plastic sheath

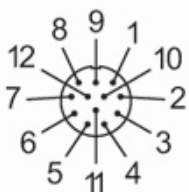

E60123



Wirable plug

SSTGK120MKRFKSG

Connection

