


Connection cable

VDOGF030MSS00,3A03STGH030MSS

Article no longer available - archive entry

Alternative articles: EVC215

When selecting an alternative article and accessories please note that technical data may differ!

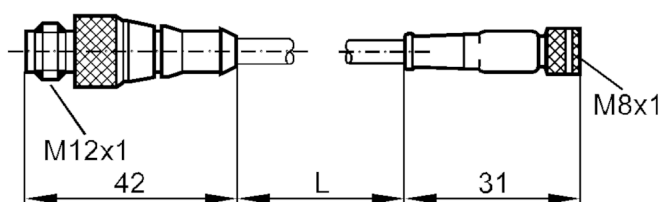

Electrical data

Operating voltage [V] 10...30 DC

Protection class III

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Materials TPU

Moulded-body material TPU

Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated



E70014




Connection cable

VDOGF030MSS00,3A03STGH030MSS

Electrical connection

Cable: 0.3 m, PUR / PVC; 3 x 0.34 mm²

Connection

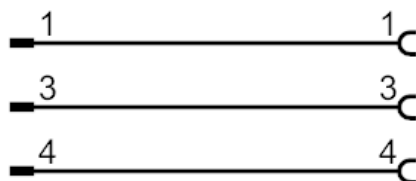

Electrical connection - socket

Connector: 1 x M8, straight; coding: A; Moulded body: TPU; Locking: brass, nickel-plated

