


E70029



Connection cable

VSTGH030MSS0010A03DOAF030MSS

Article no longer available - archive entry

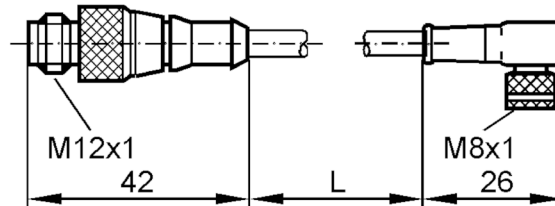

Electrical data

| | | |
|-------------------|-----|------------|
| Operating voltage | [V] | 10...30 DC |
| Protection class | | III |

Operating conditions

| | | |
|---------------------|------|----------|
| Ambient temperature | [°C] | -25...90 |
| Protection | | IP 67 |

Mechanical data

| | |
|-----------------------|----------------------|
| Materials | TPU |
| Moulded-body material | TPU |
| Material nut | brass, nickel-plated |

Remarks

| | |
|---------------|--------|
| Pack quantity | 1 pcs. |
|---------------|--------|

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated



E70029




Connection cable

VSTGH030MSS0010A03DOAF030MSS

Electrical connection

Cable: 10 m, PUR / PVC; 3 x 0.34 mm²

Connection

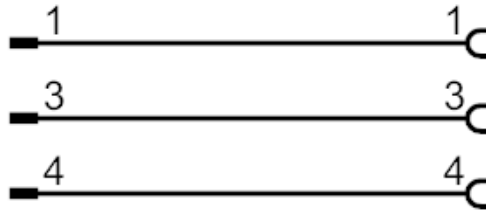

Electrical connection - socket

Connector: 1 x M8, angled; Moulded body: TPU; Locking: brass, nickel-plated

