


E70157



Connection cable

VDOGH030MSS0008A03STGH030MSS

Article no longer available - archive entry

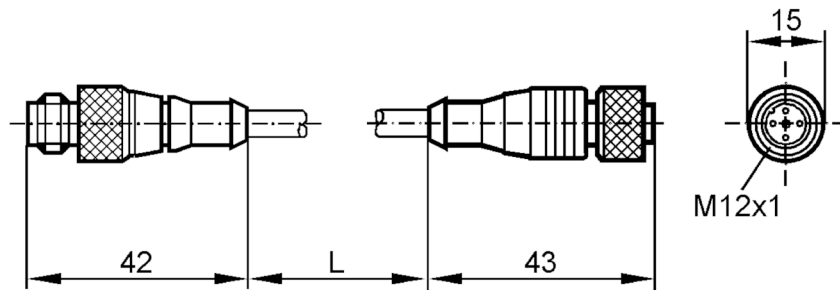

Electrical data

Operating voltage [V] 10...30 DC

Operating conditions

Ambient temperature [°C] -25...90

Protection IP 67

Mechanical data

Dimensions [mm] 15 x 15 x 42

Materials TPU

Moulded-body material TPU

 
Material nut brass, nickel-plated

Remarks

Pack quantity 1 pcs.

Electrical connection - plug

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated



E70157




Connection cable

VDOGH030MSS0008A03STGH030MSS

Electrical connection

Cable: 8 m, PUR / PVC, orange, \varnothing 5 mm; 3 x 0.34 mm² (42 x \varnothing 0.1 mm)

Connection

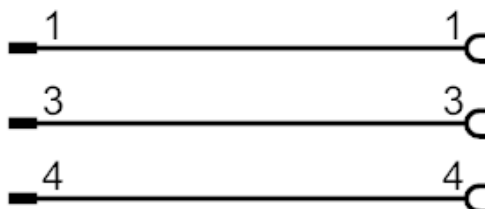

Electrical connection - socket

Connector: 1 x M12, straight; Moulded body: TPU; Locking: brass, nickel-plated

