




Splitter box

ZDO6H050MSS0010E15

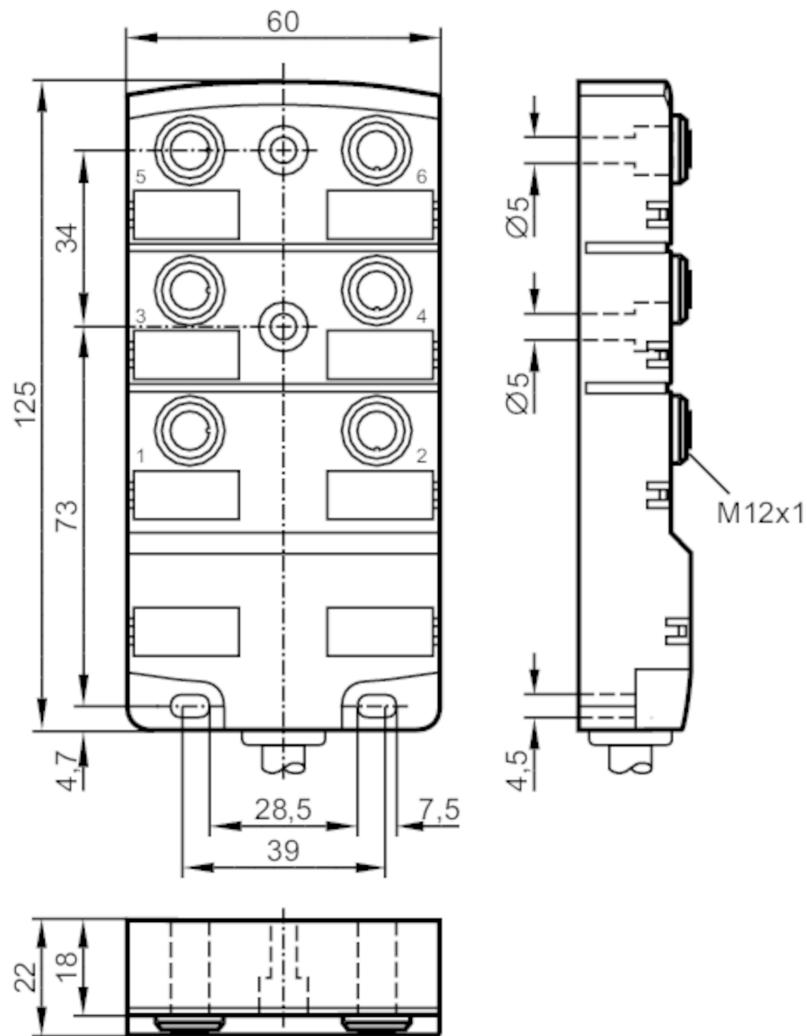

Application		
Special feature		Gold-plated contacts
Electrical data		
Operating voltage	[V]	< 30 DC; ("supply class 2" to cULus)
Max. current load per module/slot	[A]	4; (per pin: 2; per group: 8)
Max. current load total	[A]	12
Operating conditions		
Ambient temperature	[°C]	-25...40
Ambient temperature (moving)	[°C]	-5...60



Splitter box

ZDO6H050MSS0010E15

Protection	IP 67
------------	-------

Tests / approvals

UL approval	Enclosure type	Type 1
-------------	----------------	--------

Mechanical data

Weight	[g]	880
Dimensions	[mm]	22 x 60 x 125
Materials		PA
Moulded-body material		PA
Number of ports splitter box		6
Connector type		M12

Accessories

Items supplied	labels: 6
----------------	-----------

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 10 m, PVC, black, Ø 6.3 mm; 5 x 0.5 mm²

Electrical connection - slot

Connector: 6 x M12; coding: A; Moulded body: PA; Contacts: gold-plated; Tightening torque: 0.8...1.5 Nm

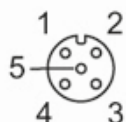




Splitter box

ZDO6H050MSS0010E15

Connection

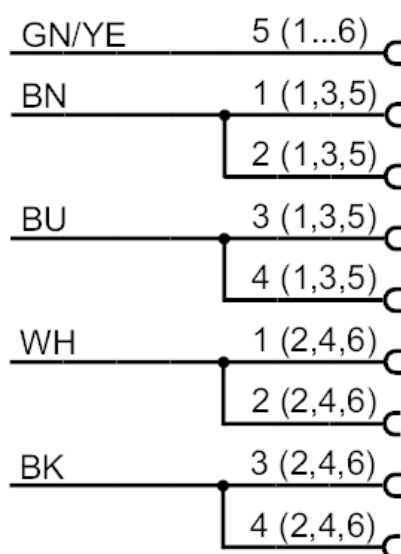

BK =	Core colours :
BN =	black
BU =	brown
GN/YE =	blue
WH =	green/yellow
	white