


## Connection cable

VDOAH030MSS0005H03STGF030MSS

Please see the technical note under "Downloads"

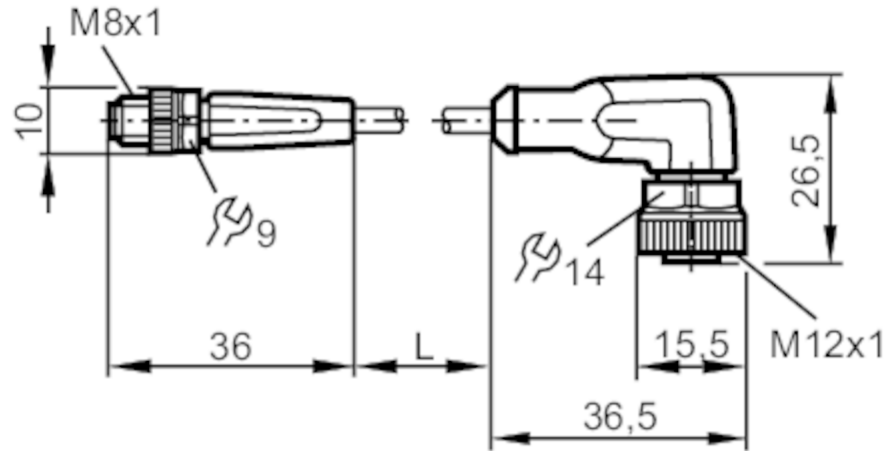

### Application

|                    |                                                                                |
|--------------------|--------------------------------------------------------------------------------|
| Special feature    | Free from silicone; Halogen-free; Gold-plated contacts; Drag chain suitability |
| Free from silicone | yes                                                                            |

### Electrical data

|                             |                   |
|-----------------------------|-------------------|
| Operating voltage [V]       | < 50 AC / < 60 DC |
| Protection class            | III               |
| Max. current load total [A] | 3                 |

### Operating conditions

|                                      |                             |
|--------------------------------------|-----------------------------|
| Ambient temperature [°C]             | -25...90                    |
| Note on ambient temperature          | cULus: ...75                |
| Ambient temperature (moving) [°C]    | -25...90                    |
| Note on ambient temperature (moving) | cULus: ...75                |
| Protection                           | IP 65; IP 67; IP 68; IP 69K |

### Mechanical data

|                        |                                   |
|------------------------|-----------------------------------|
| Weight [g]             | 154.4                             |
| Dimensions [mm]        | 10 x 10 x 36                      |
| Materials              | housing: TPU orange; Sealing: FKM |
| Material nut           | brass, nickel-plated              |
| Drag chain suitability | yes                               |



## Connection cable

VDOAH030MSS0005H03STGF030MSS

|                        |                                 |                                                                                                |
|------------------------|---------------------------------|------------------------------------------------------------------------------------------------|
| Drag chain suitability | bending radius for flexible use | min. 10 x cable diameter                                                                       |
|                        | travel speed                    | max. 3.3 m/s for a horizontal travel length of 5 m and max. acceleration of 5 m/s <sup>2</sup> |
|                        | bending cycles                  | > 5 Mio.                                                                                       |
|                        | torsional strain                | ± 180 °/m                                                                                      |

### Remarks

Notes

Please see the technical note under "Downloads"

Pack quantity

1 pcs.

### Electrical connection - plug


Connector: 1 x M8, straight; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.3...0.5 Nm



### Electrical connection

Cable: 5 m, PUR, Halogen-free, black, Ø 4.3 mm; 3 x 0.34 mm<sup>2</sup> (42 x Ø 0.1 mm )

### Connection

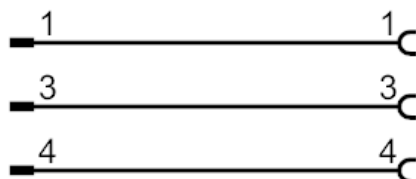

### Electrical connection - socket

Connector: 1 x M12, angled; coding: A; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 0.6...1.5 Nm

