


# OY244S



## Safety light curtain

OYA0610-30-4-20-P-1

For 8-pole sockets the core colours are not standardised.  
Please note the wiring of the sensor and the sockets (see data sheet).

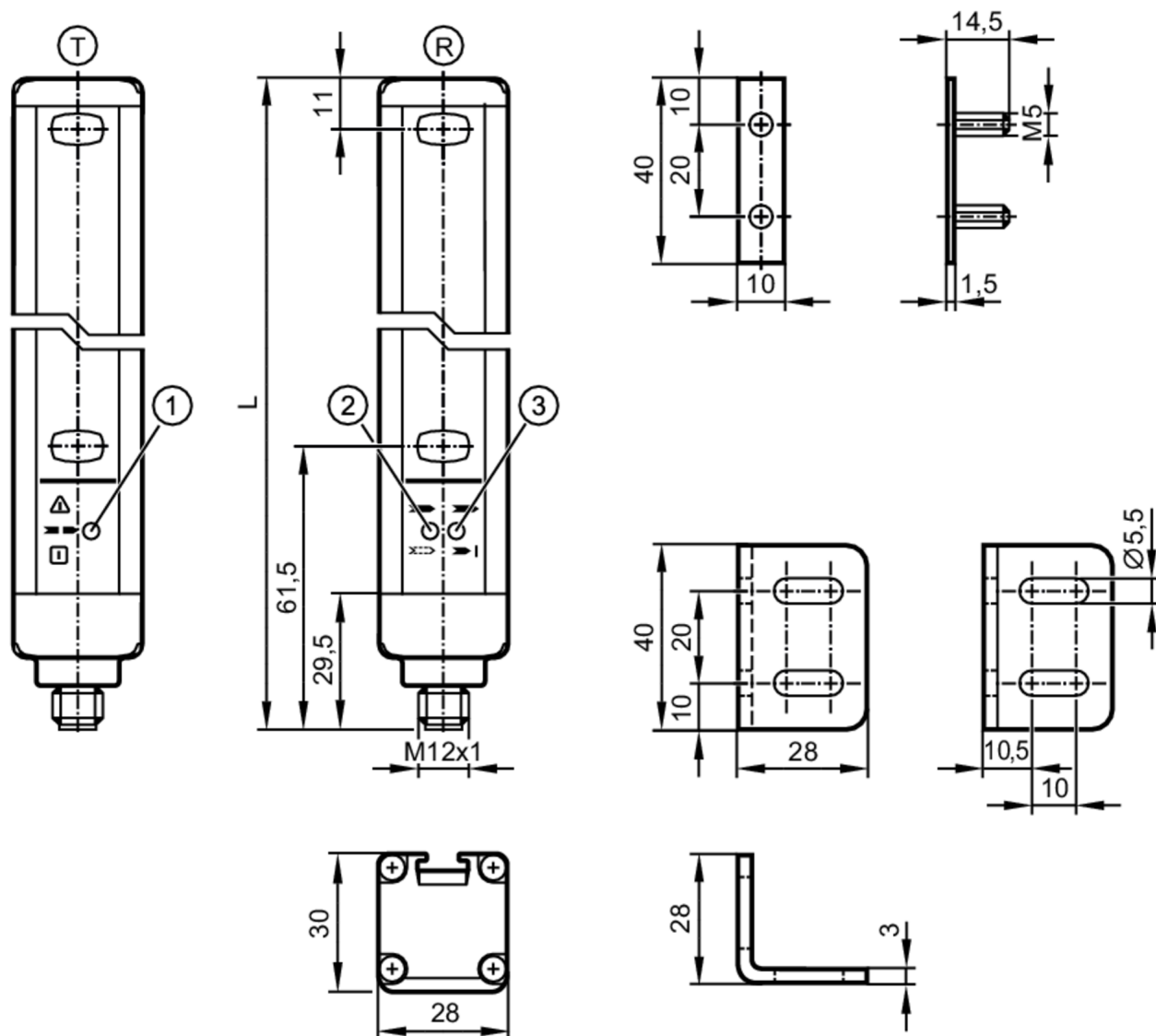

- |   |                                       |
|---|---------------------------------------|
| T | transmitter                           |
| R | receiver                              |
| 1 | LED three-colour red / green / orange |
| 2 | LED 2-colour yellow/blue              |
| 3 | LED 2-colour red/green                |



## Product characteristics

|                   |                |
|-------------------|----------------|
| Type of light     | infrared light |
| Electrical design | PNP            |
| Protection        | IP 65; IP 67   |

## Application

|                     |                                   |
|---------------------|-----------------------------------|
| Protective function | access prevention hand protection |
|---------------------|-----------------------------------|



## Safety light curtain

OYA0610-30-4-20-P-1

| Electrical data                              |             |                                                |
|----------------------------------------------|-------------|------------------------------------------------|
| Operating voltage tolerance                  | [%]         | 20                                             |
| Operating voltage                            | [V]         | 24 DC                                          |
| Protection class                             |             | III                                            |
| Reverse polarity protection                  |             | yes                                            |
| Power-on delay time                          | [s]         | < 2                                            |
| Type of light                                |             | infrared light                                 |
| Wave length                                  | [nm]        | 950                                            |
| Receiver                                     |             |                                                |
| Current consumption                          | [mA]        | 83                                             |
| Transmitter                                  |             |                                                |
| Current consumption                          | [mA]        | 42                                             |
| Outputs                                      |             |                                                |
| Electrical design                            |             | PNP                                            |
| Number of OSSD outputs                       |             | 2                                              |
| Max. current load per OSSD output            | [mA]        | 400; (24 V)                                    |
| Short-circuit protection                     |             | yes                                            |
| Detection zone                               |             |                                                |
| Protected area height                        | [mm]        | 610                                            |
| Resolution (detection capacity d)            | [mm]        | 30                                             |
| Protection area width (low light intensity)  | [m]         | 0...10                                         |
| Protection area width (high light intensity) | [m]         | 3...20                                         |
| Response times                               |             |                                                |
| Response time                                | [ms]        | 6                                              |
| Operating conditions                         |             |                                                |
| Applications                                 |             | class C to EN 60654-1 weatherproof application |
| Ambient temperature                          | [°C]        | -10...55                                       |
| Max. relative air humidity                   | [%]         | 95                                             |
| Protection                                   |             | IP 65; IP 67                                   |
| Tests / approvals                            |             |                                                |
| EMC                                          | IEC 61496-1 |                                                |
| Shock resistance                             | IEC 61496-1 |                                                |
| Vibration resistance                         | IEC 61496-1 |                                                |
| Safety classification                        |             |                                                |
| ESPE type (IEC 61496-1)                      |             | 4                                              |
| Complies with the requirements               |             | ISO 13849-1: 2015 category 4, PL e             |
|                                              |             | IEC 61508 SIL 3                                |
|                                              |             | IEC 62061 SIL 3                                |
| Mission time TM                              | [h]         | 175200                                         |
| PFH                                          | [1/h]       | 1,3E-08                                        |

OY244S




Safety light curtain

OYA0610-30-4-20-P-1

| Mechanical data                  |      |                                    |
|----------------------------------|------|------------------------------------|
| Weight                           | [g]  | 2495                               |
| Dimensions                       | [mm] | 663 x 28 x 30                      |
| Materials                        |      | housing: aluminium; front pane: PC |
| Length L                         | [mm] | 663                                |
| Displays / operating elements    |      |                                    |
| Display                          |      | LED, yellow                        |
|                                  |      | LED, green                         |
|                                  |      | LED, red                           |
|                                  |      | LED, blue                          |
|                                  |      | LED, orange                        |
| Accessories                      |      |                                    |
| Items supplied                   |      | mounting bracket: 4                |
|                                  |      | slot nuts: 4                       |
|                                  |      | Nuts                               |
| Remarks                          |      |                                    |
| Pack quantity                    |      | 1 pcs.                             |
| Electrical connection - receiver |      |                                    |

Connector: 1 x M12; coding: A; Maximum cable length: 100 m; for wire cross-section 0.34 mm²

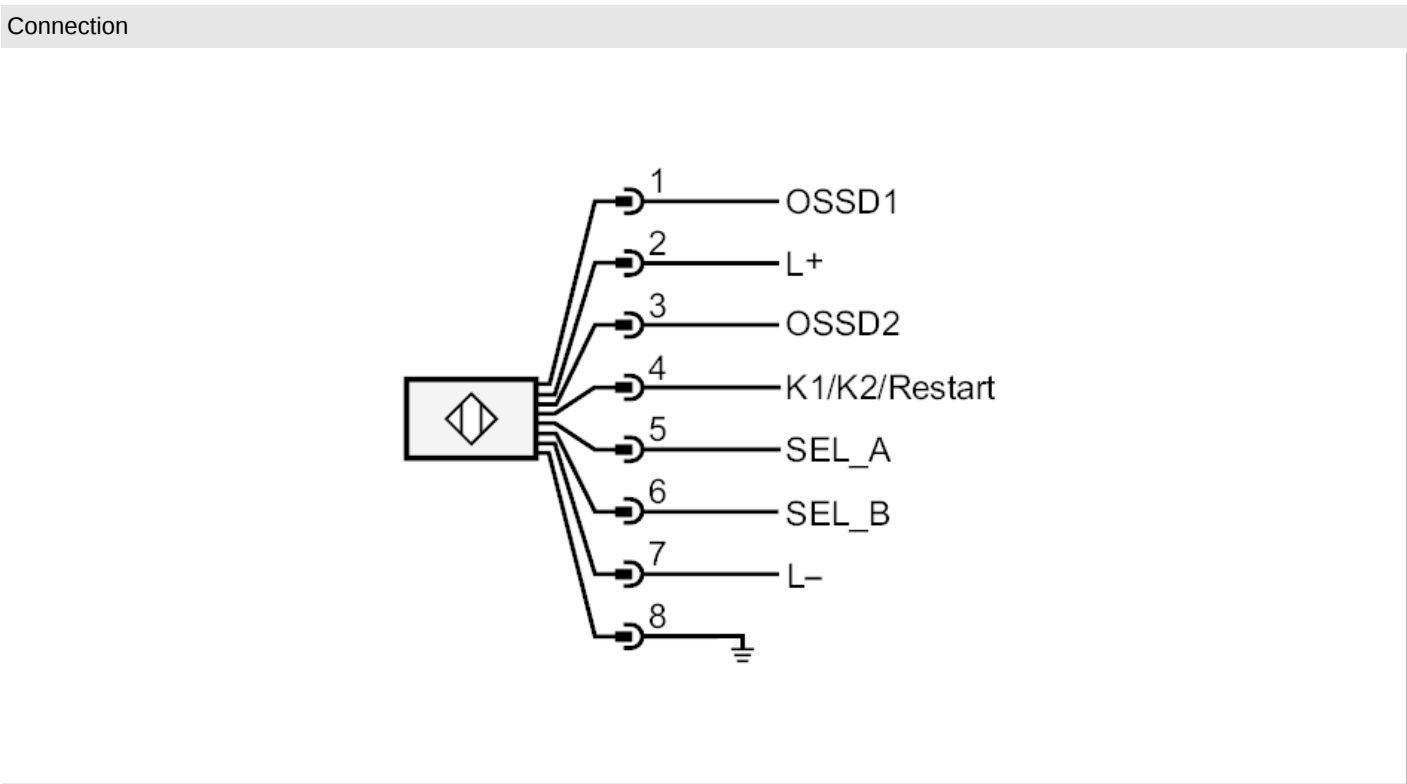

# OY244S




## Safety light curtain

OYA0610-30-4-20-P-1

### Electrical connection - transmitter

Connector: 1 x M12; coding: A

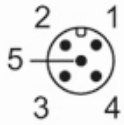

### Connection

