


Control monitor for flow sensors

VS0200/ 30- 60VDC/30- 42VAC

Article no longer available - archive entry

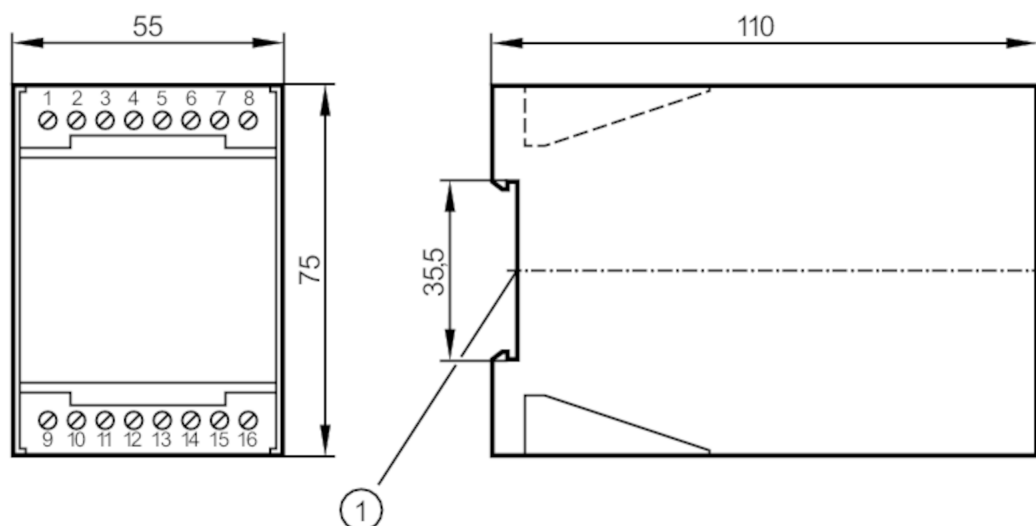

1 mounting on DIN rail



Application

Application Flow monitoring

Electrical data

Operating voltage	[V]	30...42 AC / 30...60 DC
Power-on delay time	[s]	30
Number of channels		1

Outputs

Electrical design	relay
Contact rating	4 A, 250 V AC
Switching function flow monitoring	relay energised when flow is present

Software / programming

Adjustment of the switch point	potentiometer
Selection liquids / gases	slide switch

Operating conditions

Ambient temperature	[°C]	0...60
Protection		IP 40
Protection rating terminals		IP 20

Mechanical data

Housing	housing for DIN rail mounting	
Dimensions	[mm]	75 x 55 x 110
Materials		plastics

SB0100



Control monitor for flow sensors

VS0200/ 30- 60VDC/30- 42VAC

Displays / operating elements

Display	function	11 x LED
---------	----------	----------


Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

terminals: 16 x ...2.5 mm²

Connection

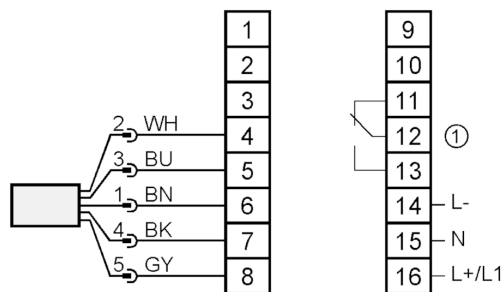

- 1: Relais Flow monitoring
Core colours :
BN = brown
BU = blue
BK = black
WH = white
GY = grey