


U60121



Temperature probe sensor

SURFACE MOUNT RTD, WELD

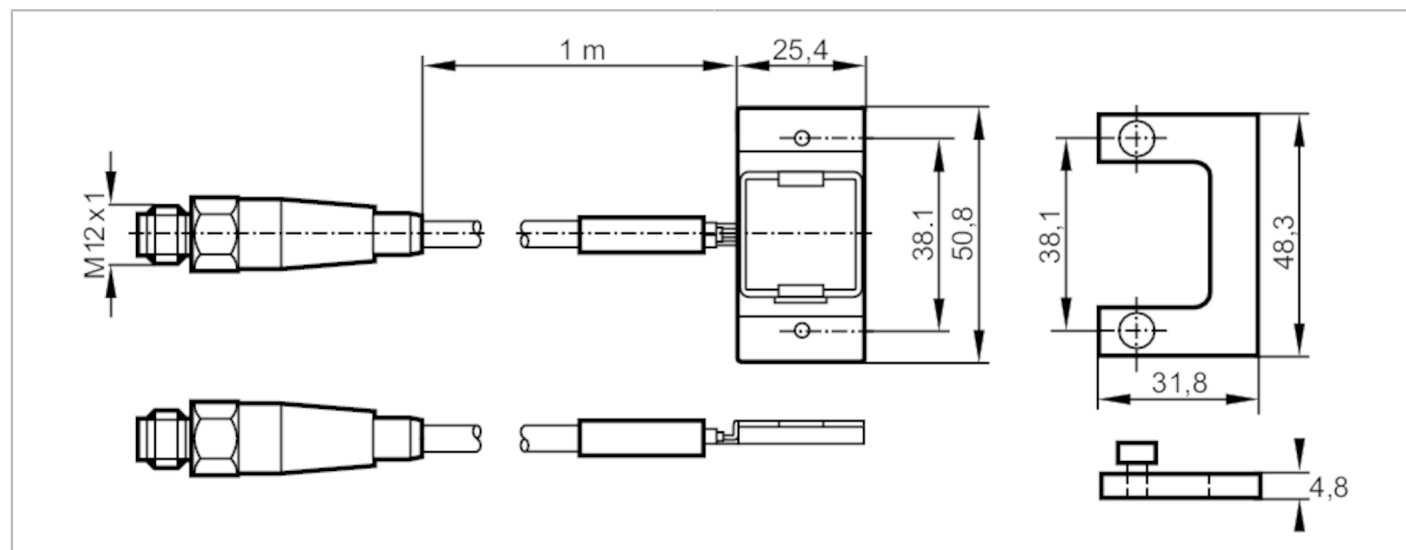

Product characteristics

Measuring range	-200...232 °C	-320...450 °F
-----------------	---------------	---------------

Application

Measuring element	1 x Pt 100; (to DIN EN 60751, class B)
Installation	surface mount RTD with welding bracket

Measuring/setting range

Measuring range	-200...232 °C	-320...450 °F
-----------------	---------------	---------------

Accuracy / deviations

Long-term stability	< 0,05 °C; (temperature drift per 5 years)
---------------------	--

Operating conditions

Ambient temperature	[°C]	-25...80
Note on ambient temperature		plug area
Protection		IP 67

Mechanical data

Weight	[g]	90.718
Housing		bolt-on sensor
Materials		stainless steel (302); stainless steel (304); silicone rubber; Angle bracket: stainless steel; screws: stainless steel

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 1 m, PVC

Connector: 1 x M12; coding: A



U60121



Temperature probe sensor

SURFACE MOUNT RTD, WELD

Connection

