


Connecting cable with socket

ADOGA040MKS0005E04

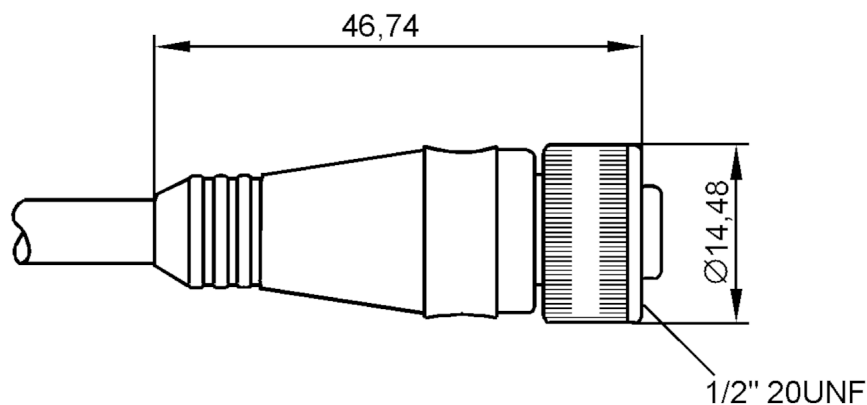

Electrical data

Operating voltage	[V]	< 300 AC/DC
-------------------	-----	-------------

Operating conditions

Ambient temperature	[°C]	-20...105
Protection		IP 68

Mechanical data

Weight	[g]	362.874
Dimensions	[mm]	14.5 x 14.5 x 46.7
Materials		PVC
Moulded-body material		PVC
Material nut		diecast zinc

Remarks


Pack quantity	1 pcs.
---------------	--------

Electrical connection

Cable: 4.57 m, PVC, yellow, Ø 7.37 mm; 4 x 0.75 mm² / AWG 18

Electrical connection - socket

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: diecast zinc

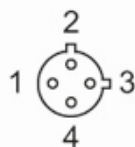


W80135



Connecting cable with socket

ADOGA040MKS0005E04

Connection

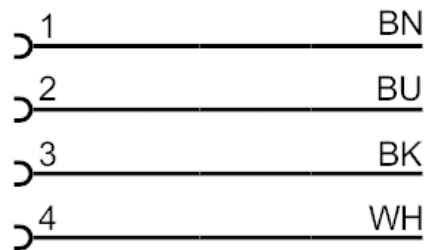

	Core colours :
BK =	black
BN =	brown
BU =	blue
WH =	white