


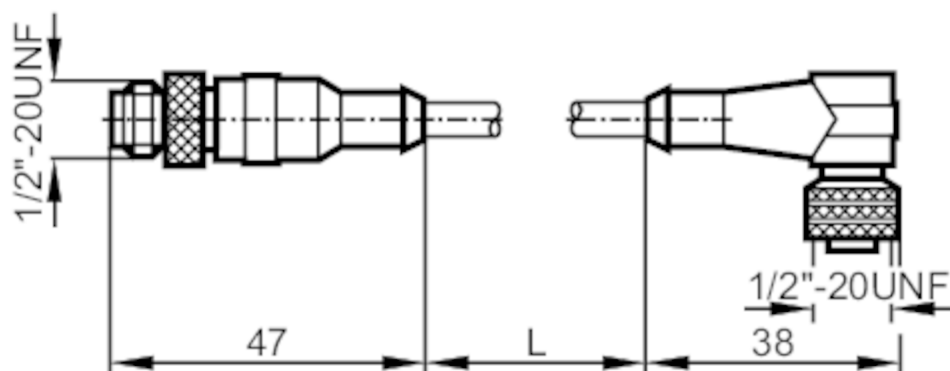

Connection cable

VDOGA030MKS0001E03STAA030MKS



Application

Special feature

Gold-plated contacts

Electrical data

Operating voltage	[V]	< 250 AC
Max. current load total	[A]	3

Operating conditions

Ambient temperature	[°C]	-25...85
Protection		IP 68

Mechanical data

Weight	[g]	72.575
Materials		PVC
Moulded-body material		PVC
Material nut		zinc, epoxy coated

Remarks

Pack quantity	1 pcs.
---------------	--------

Electrical connection - plug

Connector: 1 x 1/2", straight; coding: C; Moulded body: PVC; Locking: zinc, epoxy coated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm



W93005




Connection cable

VDOGA030MKS0001E03STAA030MKS

Electrical connection

Cable: 1 m, PVC, yellow, Ø 4.3 mm; 3 x 0.34 mm² (42 x Ø 0.1 mm)

Connection

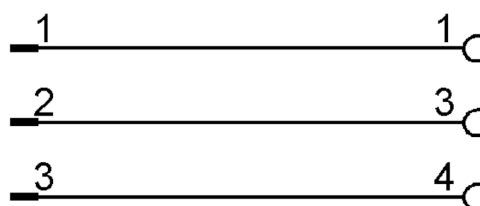

Electrical connection - socket

Connector: 1 x 1/2", angled; coding: C; Moulded body: PVC; Locking: zinc, epoxy coated; Contacts: gold-plated; Tightening torque: 0.7...0.9 Nm

