


E10822



Jumper cable with valve plug

VVDAA040--N00,6E02STAH020VAN

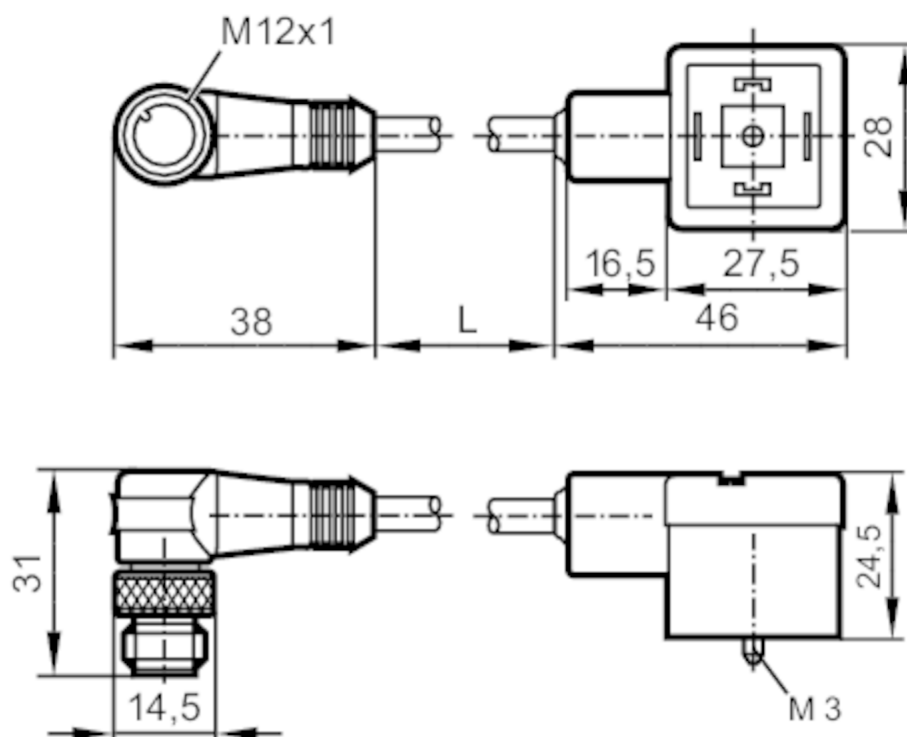

Application	
Application	NAMUR
Electrical data	
Operating voltage [V]	< 15 DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 67
Mechanical data	
Weight [g]	62.2
Dimensions [mm]	31 x 14.5 x 38
Materials	TPU; PUR
Moulded-body material	TPU / PUR
Material nut	stainless steel (316L/1.4404)
Accessories	
Items supplied	screw panel for labelling
Remarks	
Remarks	For use in zone 0, group IIB or IIC the user has to avoid intensive electrostatic charge build-up at the sockets.
Pack quantity	1 pcs.

E10822



Jumper cable with valve plug

VVDAA040--N00,6E02STAH020VAN

Electrical connection - plug

Connector: 1 x M12, angled; coding: A; Moulded body: TPU / PUR; Locking: stainless steel (316L/1.4404)



Electrical connection

Cable: 0.6 m, PVC, blue, Ø 5.1 mm; 2 x 0.5 mm²

Connection



Electrical connection - socket

Connector: 1 x valve type A DIN, angled; Moulded body: TPU / PUR; Locking: stainless steel (316L/1.4404)

