


E11174



Connecting cable with socket

ADOAH040MSS0010H04

Article no longer available - archive entry

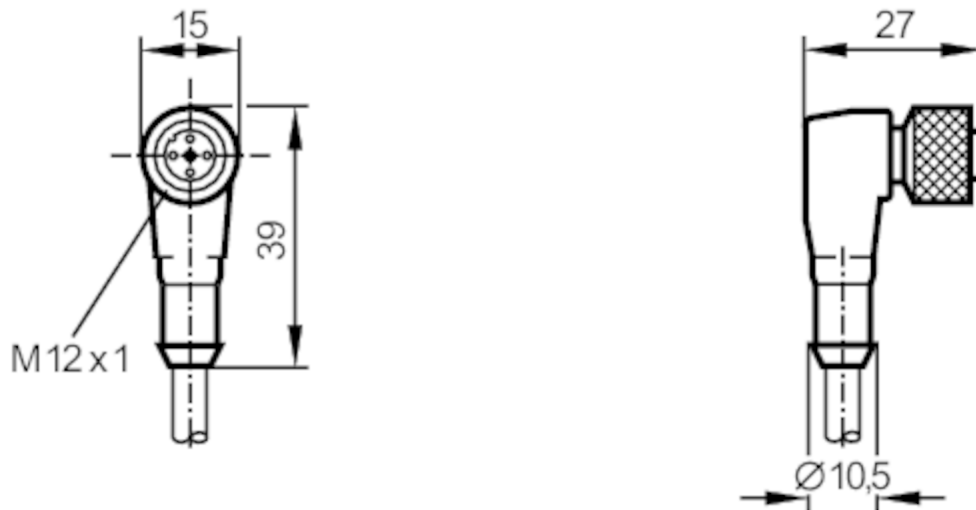

Application	
Special feature	Free from silicone; Halogen-free; Gold-plated contacts
Free from silicone	yes
Electrical data	
Operating voltage [V]	< 250 AC / < 300 DC
Operating conditions	
Ambient temperature [°C]	-25...90
Protection	IP 68
Mechanical data	
Dimensions [mm]	27 x 15 x 39
Materials	TPU
Material nut	brass, nickel-plated
Remarks	
Pack quantity	1 pcs.
Electrical connection	
Cable: 10 m, PUR, Halogen-free, grey, Ø 5 mm; 4 x 0.34 mm ² (42 x Ø 0.1 mm)	
Electrical connection - socket	
Connector: 1 x M12, angled; Moulded body: TPU; Locking: brass, nickel-plated; Contacts: gold-plated	

E11174




Connecting cable with socket

ADOAH040MSS0010H04



Connection

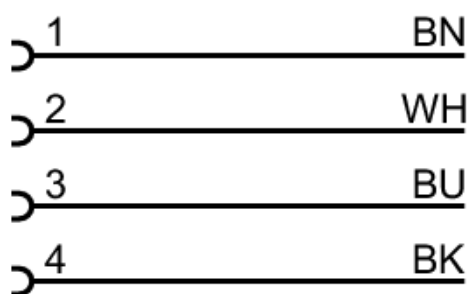

Core colours :

BK = black
BN = brown
BU = blue
WH = white

Article no longer available - archive entry