


E12642



Connecting cable with socket

ADOGX050MSS0005H05

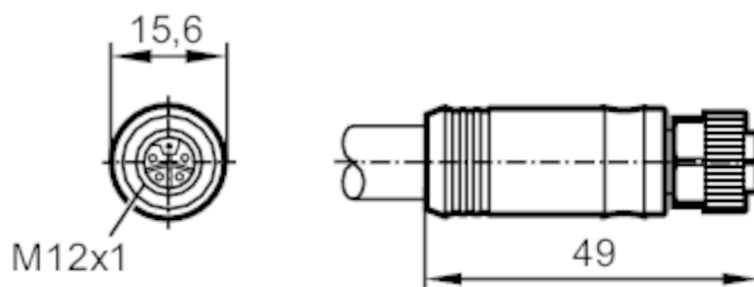

Application

Special feature	Gold-plated contacts
Design	power cable, L-coded

Electrical data

Operating voltage	[V]	63 DC
Max. current load total	[A]	16

Operating conditions

Ambient temperature	[°C]	-40...90
Protection		IP 67

Mechanical data

Weight	[g]	1082.5
Dimensions	[mm]	49 x 15.6 x 15.6
Materials		PP
Moulded-body material		TPE
Material nut		brass, nickel-plated

Remarks

Pack quantity	1 pcs.
---------------	--------

E12642



Connecting cable with socket

ADOGX050MSS0005H05

Electrical connection

Cable: 5 m, PUR, black, Ø 11.3 mm; 5 x 2.5 mm²

Electrical connection - socket

Connector: 1 x M12, straight; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



Connection

1	BN
2	WH
3	BU
4	BK
5	GY