


E12652



Connection cable

VDOGX050MSS00,5H05STGH005MSS

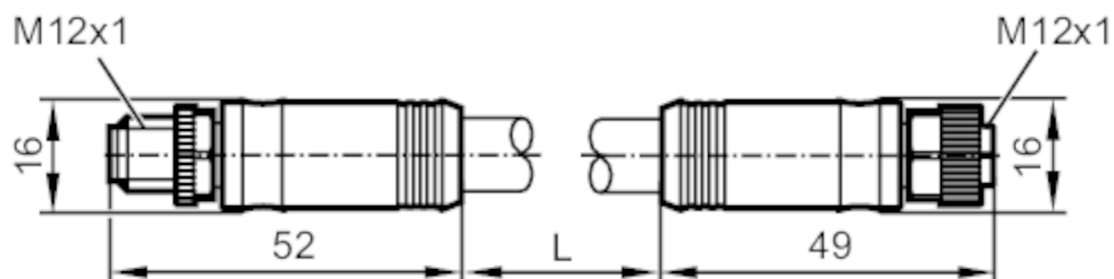

Application

Special feature	Gold-plated contacts
Design	power cable, L-coded

Electrical data

Operating voltage	[V]	64 DC
Max. current load total	[A]	16

Operating conditions

Ambient temperature	[°C]	-40...90
Protection		IP 67

Mechanical data

Weight	[g]	139.8
Materials		PP
Moulded-body material		TPE
Material nut		brass, nickel-plated

Remarks

Pack quantity		1 pcs.
---------------	--	--------

E12652



Connection cable

VDOGX050MSS00,5H05STGH005MSS

Electrical connection

Cable: 0.5 m, PUR, black, Ø 11.3 mm; 5 x 2.5 mm²


Electrical connection - plug

Connector: 1 x M12, straight; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated



Electrical connection - 2

Connection

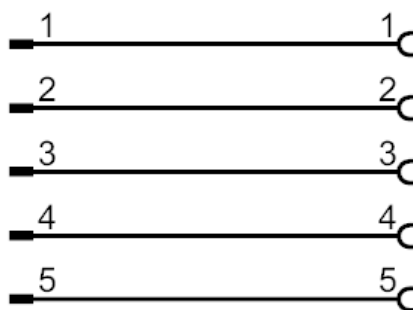

Electrical connection - socket

Connector: 1 x M12, straight; coding: L; Moulded body: TPE; Locking: brass, nickel-plated; Contacts: gold-plated

