




Fibre optic diffuse reflection sensor

FT-00-P-V-E1/S 0,1m

Article no longer available - archive entry

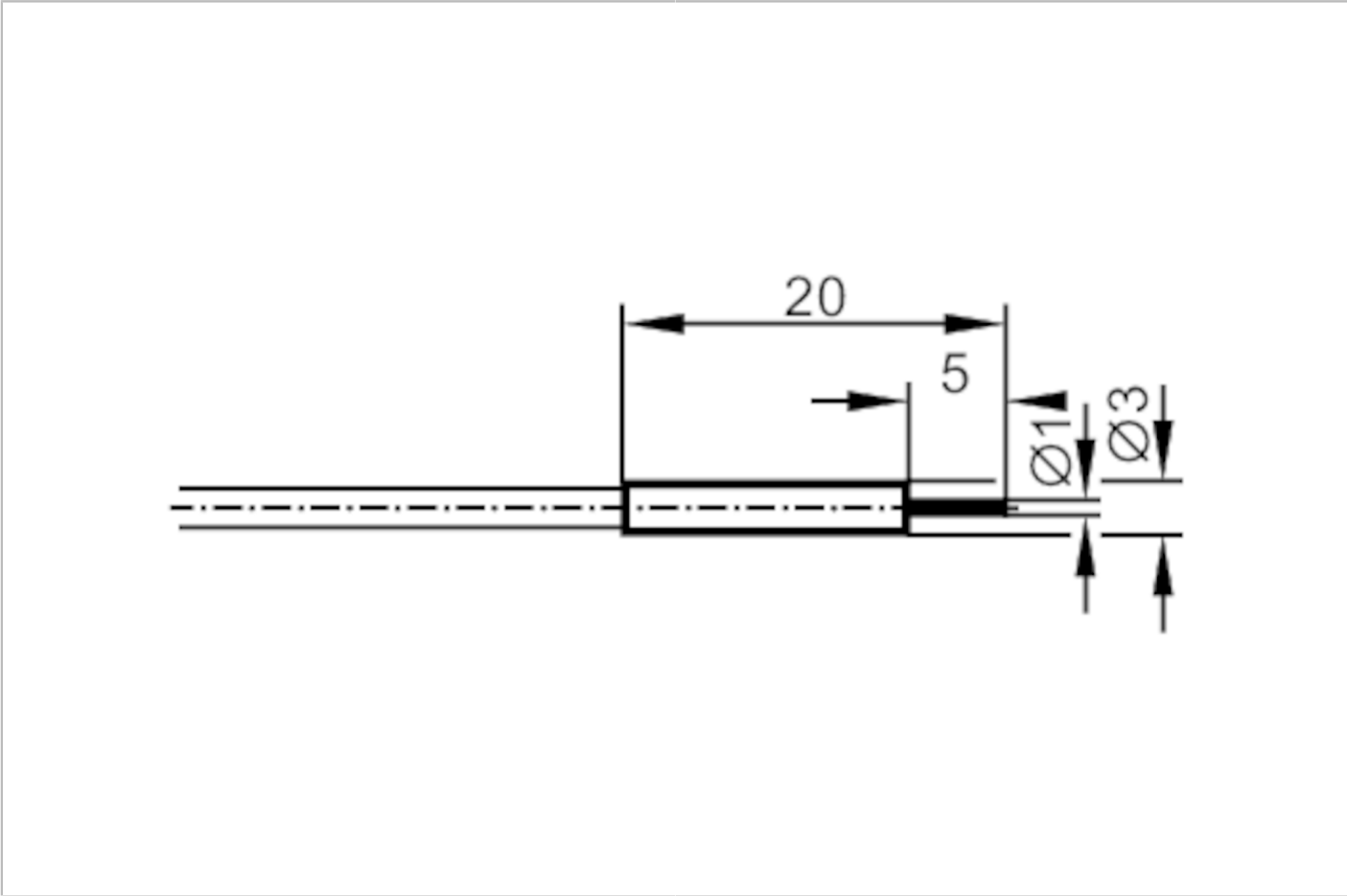

Application	
Function principle	Through-beam sensor
Detection zone	
Range with fibre-optic amplifier type	OKF; OUF
OKF	
Range of fibre optics [mm]	50
OUF	
Range of fibre optics [mm]	50
Operating conditions	
Ambient temperature [°C]	-20...80
Mechanical data	
Version of sensing head	straight
Sensing head diameter [mm]	1
Sensing head length [mm]	5
Total length [mm]	100
Min. bending radius [mm]	10
Materials	Adapter: PPE
Fibre material	glass

E20444



Fibre optic diffuse reflection sensor

FT-00-P-V-E1/S 0,1m

Fibre head material	stainless steel (1.4305 / 303)
Fibre sheath material	PVC
Remarks	
Pack quantity	1 pcs.